



Product Compliance


For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Low Bromine/Chlorine - Br and Cl < 900 ppm per homogenous material. Also BFR /CFR/PVC Free
Solder Process Capability	Wave solder capable to 265°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

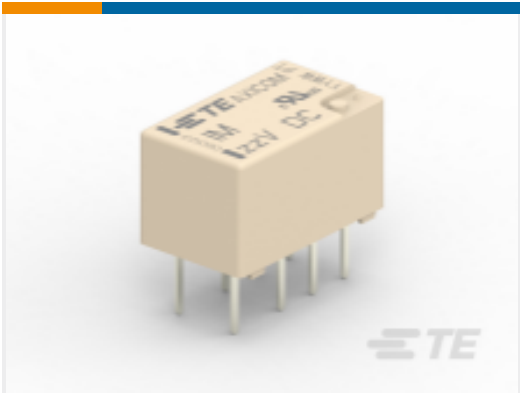



TE Part # CAT-AX41-IM11A

Narrow Signal Relay 2 Form C, 2 CO

Cont

Customers Also Bought

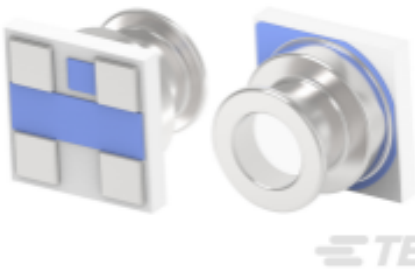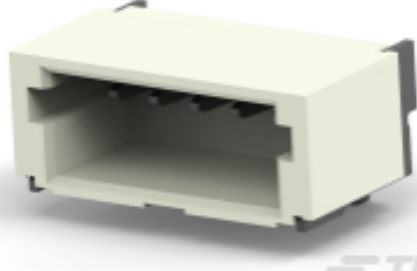

 TE Part #MS561101BA03-50 BOARD LEVEL PRESSURE STOCK LIST	 TE Part #1-2176054-4 Thick Film Resistor: Current Sense	 TE Part #1-1734595-1 AMP HPI 1.0MM HEADERS	 TE Part #1625854-2 0805 PROBE PAD
 TE Part #1623107-1 CRG0805 1% 120R	 TE Part #2-2176186-0 CRGH1206 1% 4K7 0.5W	 TE Part #1-215460-8 MICRO-MATCH FEM.SE	 TE Part #1-967657-1 SIGNAL HEADER
 TE Part #1623401-1 CRG0805 ZEROHM	 TE Part #1775838-2 mSATA/mini PCI-E 5.6H Type I G/F		

Documents

Product Drawings

IM06PNS=IM RELAY 140 MW 12V

English

IM06PNS=IM RELAY 140 MW 12V

English

Datasheets & Catalog Pages

Transportation, Storage, Handling, Assembly and Testing of Axicom Through Hole Terminal (THT) Relays

English

IM_Datasheet PCN P-20-019002

English

Industrial Relays Quick Reference Guide

English

Industrial Relays Quick Reference Guide

Japanese

Industrial Relays Quick Reference Guide

Product Specifications



Definitions, Handling, Processing, Testing and Use of Relays

English