



All NC NYLON CLOTH LABELS (19)

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts





TE Part # 1-2186500-1
T3212-PRINTER




TE Part # 1-2186502-1
T3224-PRINTER



TE Part # 1-2186503-1
T3224-SWARE-PRINTER



TE Part # 1-2186501-1
T3212-SWARE-PRINTER

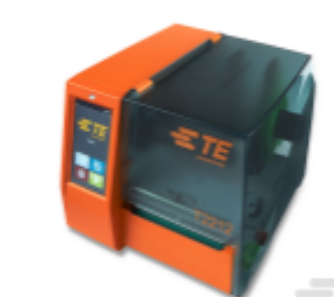

TE Part # 1-2186527-1
T2212-PRINTER



TE Part # 1-2186528-1
T2212-SWARE-PRINTER

Also in the Series | Agastat E7000




Standard Labels(19)




Time Delay Relays(27)

Customers Also Bought

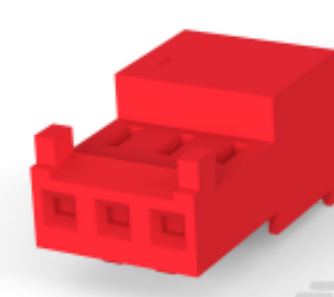


TE Part #3-643815-8
Nylon Tin Plated Receptacle: 2.54mm, With Mating Alignment, MTA 100

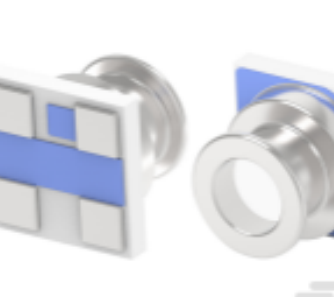


TE Part #MS580301BA01-00
BOARD LEVEL PRESSURE STOCK LIST



TE Part #1375820-2
Receptacle Housing: 2.54mm, 1 Row, CST-100 II

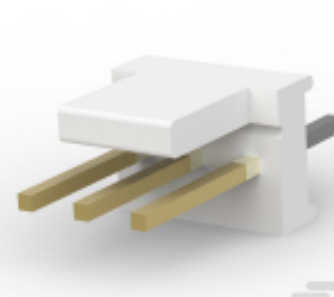

TE Part #1-640454-4
Polyester Vertical PCB Header: 2.54 mm, With Mating Alignment, Unshrouded

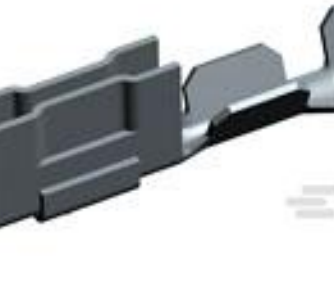

TE Part #1375819-1
CST-100 II CONTACT TIN PLT



TE Part #1658606-1
IDC D-Sub: Receptacle Assembly, Low Profile, Signal, 2.77 mm



TE Part #1-794606-2
MICRO MNL RPT CNT STRP 30AU LF



Documents

Product Drawings

NC-254097-10-9

English

Datasheets & Catalog Pages

NC Nylon Cloth Labels

English

411-121050 Flag Labelling - User Guide

English

IDENTIFICATION SELECTION GUIDE

English

Product Specifications

Manuals & User Guides

English