

7" LCD TOUCHSCREEN

Capacitive touch IPS display



This 7" touch display convinces with its variety of different application possibilities.

The display can be connected via HDMI as well as via VGA.

It has a 3.5 mm audio connector and a 4-pin JST-connector, to which headphones or two 2 W / 5 Ω speakers can be connected.

The integrated software allows you to configure settings such as contrast and brightness using the buttons on the side.

MAIN FEATURES


Model	7" LCD Touchscreen
LCD type	IPS
Resolution	1024 x 600
Contrast	800:1
Brightness	350 CD/m ²
Multitouch	Capacitive; 5 Points
Connections	HDMI, VGA, Audio 3.5 mm, JST connector for two 2 W / 5 Ω speaker
Power supply	5 V / 2 A

FURTHER SPECIFICATION

Viewing angle	175°
Colours	16,7 M
Further special features	Additional solder pads to lead the buttons to the
Operating temperature	-10 to 60 °C
Dimensions	165 x 124 x 13 mm
Items delivered	Display, microUSB-cable, VGA-cable, HDMI-cable, HDMI-microHDMI-cable

FURTHER DETAILS

Article No.	RB-LCD-7-3
EAN:	4250236822259
Customs Tariff No.	8473302000

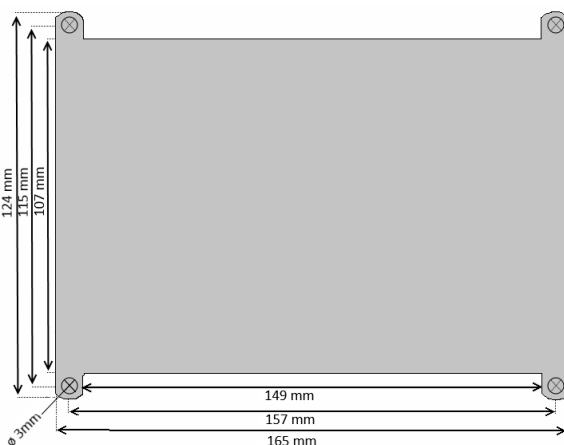

Published: 09.12.2021