

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0002061103**
Status: **Active**
Overview: Standard .062"+ and Standard .062" Pin and Socket Connector Systems
Description: 1.57mm Diameter, Standard .062" Pin and Socket Crimp Terminal, Female, with Tin (Sn) Plated Brass Contact, 18-24 AWG, Bag

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-1190-003-001 \(PDF\)](#)

General

Product Family	Crimp Terminals
Series	<u>1561</u>
Application	Power
Crimp Quality Equipment	Yes
Overview	<u>Standard .062"+ and Standard .062" Pin and Socket Connector Systems</u>
Packaging Alternative	<u>02061101 (Reel)</u>
Product Name	Standard .062"
UPC	800753615991

Physical

Gender	Female
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.147/g
Packaging Type	Bag
Plating min - Mating	0.508µm
Plating min - Termination	0.508µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.52-3.05mm
Wire Size AWG	18, 20, 22, 24
Wire Size mm ²	N/A

Solder Process Data


Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Engineering Number	1561-(P901)L
--------------------	--------------

Reference - Drawing Numbers

Packaging Specification	PK-1190-003-001
Sales Drawing	SD-1561-X-001

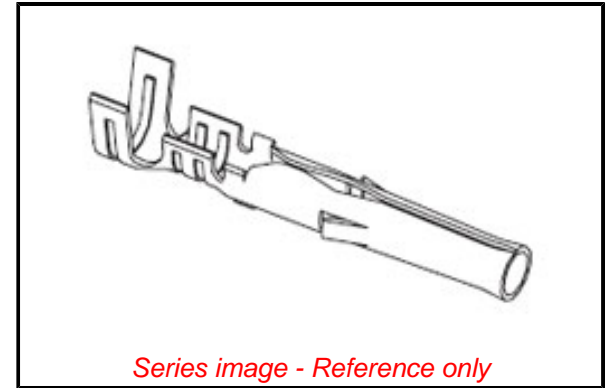

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

1561 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Insertion Tool for Standard .062" Diameter Male and Female Terminals	<u>11020001</u>
Extraction Tool for Standard .062" and Standard .062"+ Pin and Socket Terminals	<u>11030002</u>
ServiceGrade Hand Crimp Tool for Field Repair Only, 14-24 AWG	<u>638111000</u>

Hand Crimp Tool for [638191300](#)
Standard 1.57mm
Pin and Socket
Crimp Terminals,
18-24 AWG

This document was generated on 07/05/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION