

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0002098108

Status:

Active

Overview:

Standard .093" Pin and Socket Connectors

Description:

2.36mm Diameter, Standard .093" Pin and Socket Double Crimp Grounding Terminal, Series 1973, Male, with Tin (Sn) Plated Brass Contact, 14-18 AWG, Reel

Documents:

Drawing (PDF)


Product Specification PS-02-09-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	1973
Application	Power, Wire-to-Wire
Comments	Grounding Pin
Crimp Quality Equipment	Yes
Overview	Standard .093" Pin and Socket Connectors
Product Name	Standard .093"
UPC	800754320788
Physical	
Durability (mating cycles max)	25
Gender	Male
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.269/g
Packaging Type	Reel
Plating min - Mating	0.508µm
Plating min - Termination	0.508µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.65-3.56mm
Wire Size AWG	14, 16, 16+18, 18, 18+18
Wire Size mm²	N/A

Material Info	
Engineering Number	1973-2A(P901)

Reference - Drawing Numbers	
Product Specification	PS-02-09-001
Sales Drawing	SD-1973-X-001

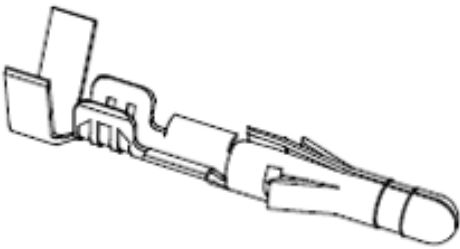

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
1973 Series

Use With
1619 Plug or Receptacle Housing,
1545 Plug or Receptacle Housing, 1396
Plug or Receptacle Housing, 1490 Plug
or Receptacle Housing, 2629 Plug or
Receptacle Crimp Housings, 1261 Plug or
Receptacle Housing, 1292 Plug or Recept

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Extraction Tool for Standard .093" Pin and Socket Terminals	11030006
Terminator Die	11402214

Extractor Tool for .093 and HCS-125 Product Series	<u>638240200</u>
Mini-Mac Applicator for Standard .093" Pin and Socket Terminals, for 14-20 AWG Wire with Insulation Diameter 1.65-4.06mm	<u>638927100</u>
Mini-Mac Applicator for Standard .093" Pin and Socket Terminals, for 14-20 AWG Wire with Insulation Diameter 1.65-4.06mm	<u>638927300</u>

This document was generated on 08/17/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION