

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0008500008
Status: Active
Overview: KK Interconnect Solutions
Description: KK 396 Crimp Terminal 8818, 18-22 AWG, Reel, Brass Tin (Sn)

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-08-50-001 \(PDF\)](#)
[Packaging Specification PK-2759-002-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Crimp Terminals
Series 8818
Application Power, Wire-to-Board
Crimp Quality Equipment Yes
Overview KK Interconnect Solutions
Packaging Alternative 08500023 (Loose)
Product Name KK 396
UPC 800753617889

Physical
Gender Female
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 0.180/g
Packaging Type Reel
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 2.41mm max.
Wire Size AWG 18, 20, 22
Wire Size mm² N/A

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number 8818-(P909)

Reference - Drawing Numbers
[Packaging Specification](#) PK-2759-002-001
[Product Specification](#) PS-08-50-001
[Sales Drawing](#) SD-8818-001

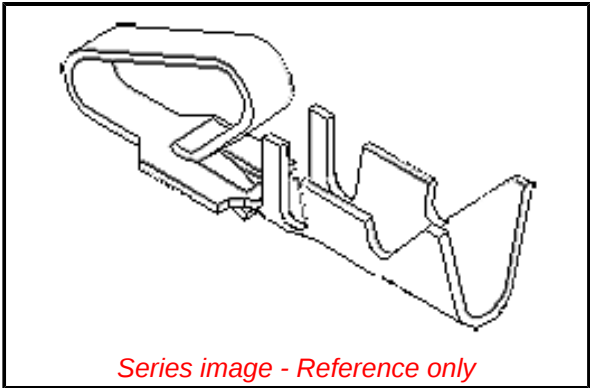

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS Green Image ELV Not Relevant RoHS Phthalates Not Contained
--	--

Search Parts in this Series
8818 Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
Hand Crimp Tool for 3.96mm Pitch KK Crimp Terminals, 18-22 AWG Mini-Mac Applicator	638280300 638881100

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION