

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0008650804

Status:

Active

Overview:

KK Interconnect Solutions

Description:

KK 254 Cat Ear Crimp Terminal 41572, Reel Tin (Sn)

Documents:

Drawing (PDF)

Packaging Specification PK-2759-002-001 (PDF)


RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	41572
Application	Signal, Wire-to-Board
Crimp Quality Equipment	Yes
Overview	KK Interconnect Solutions
Packaging Alternative	08650805 (Loose)
Product Name	Cat Ear, KK 254
UPC	800753641143
Physical	
Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.061/g
Packaging Type	Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.57mm max.
Wire Size AWG	22, 24, 26, 28, 30
Wire Size mm²	N/A

Solder Process Data	
Lead-freeProcess Capability	N/A

Material Info	
Engineering Number	41572-A(P909)

Reference - Drawing Numbers	
Packaging Specification	PK-2759-002-001
Sales Drawing	SD-41572-001

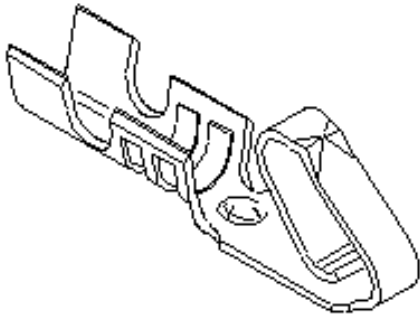

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

41572 Series

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Extraction Tool for KK 2.54mm Terminals, 22-30 AWG	11030022
Terminator Die	11402265
Insertion Tool for KK 2.54mm Terminals, 22-30 AWG	638120000
Mini-Mac Applicator for KK and Cat Ear Terminals for 22-30 AWG Wire with Insulation Diameter 1.09-1.57mm	638882000

and 22-28
AWG Wire with
Insulation Diameter
1.20-1.70mm
Mini-Mac Applicator 638882100
for KK and Cat Ear
Terminals for 22-30
AWG Wire with
Insulation Diameter
0.96-1.20mm

This document was generated on 08/18/2021
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION