

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200845107](#)
Status: **Active**
Overview: Brad Ultra-Lock Connection System
Description: Ultra-Lock (M12) Receptacle, 4 Poles, M16x1.5 Mounting Threads, Female (Straight) to 0.34mm² PVC Leads, 0.30m (11.81") Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Receptacles
 Series [120025](#)
 IP Rating IP69K
 NEMA Rating NEMA 6
 Overview [Brad Ultra-Lock Connection System](#)
 Product Name Ultra-Lock (M12)
 Type Single Ended (pigtail)
 UPC 883906778804

Physical

Coupling Type Internal Thread
 Gender Female
 Keyway Single
 Length 0.30m
 Material - Component Nickel-plated Brass
 Mounting Thread Size M16 x 1.5
 Net Weight 333.000/g
 Orientation Straight
 Panel Mount Front
 Poles 4
 Temperature Range - Operating -25°C to +90°C
 Wire Size AWG 22
 Wire/Cable Type Leads, UL 1061

Electrical


Current - Maximum per Contact 4.0A
 Voltage - Maximum 250V AC/DC

Material Info

Engineering Number WR4U20E03C3003

Reference - Drawing Numbers

Sales Drawing 1200845107-000

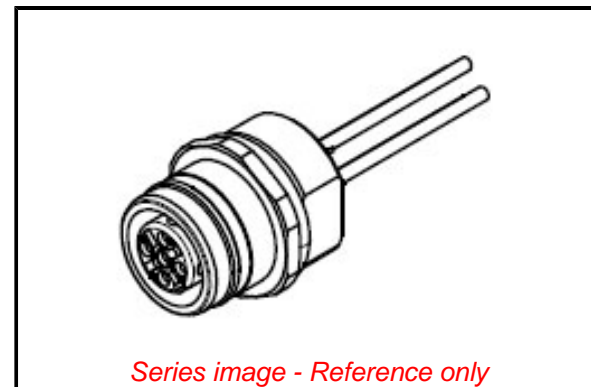

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Contained Per -
 D(2020)9139-DC (19
 Jan 2021)

Lead

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Not Relevant

Compliant

Not Contained

Search Parts in this Series

[120025 Series](#)