

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200845154](#)
Status: **Active**
Overview: [Brad Ultra-Lock Connection System](#)
Description: Ultra-Lock (M12) Receptacle, 4 Poles, PG9 Mounting Threads, Female (Straight) to 0.34mm² PVC Leads, 0.30m (11.81") Length , PG9

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Receptacles
Series	120084
IP Rating	IP69K
NEMA Rating	NEMA 6
Overview	Brad Ultra-Lock Connection System
Product Name	Ultra-Lock (M12)
Type	Single Ended (pigtail)
UPC	884982225251

Physical

Coupling Type	Internal Thread
Gender	Female
Keyway	Reverse
Length	0.30m
Material - Component	Nickel-plated Brass
Mounting Thread Size	PG9
Net Weight	20.180/g
Orientation	Straight
Panel Mount	Front
Poles	4
Temperature Range - Operating	-25°C to +90°C
Wire Size AWG	22
Wire/Cable Type	Leads, UL 1061

Electrical


Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC

Material Info

Engineering Number	WR4J20E03C3003
--------------------	----------------

Reference - Drawing Numbers

Sales Drawing	SD-120084-030-001
---------------	-------------------

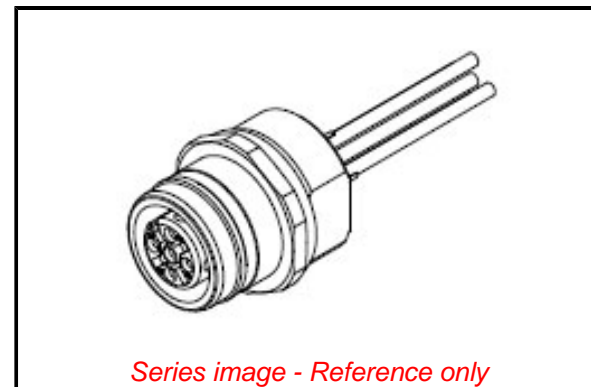

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c),7(c)-I

REACH SVHC

Contained Per - D(2020)9139-DC (19 Jan 2021)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[120084 Series](#)