


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 1201190042
Status: Active
Overview: Brad Ultra-Lock Connection System
Description: Ultra-Lock (M12) Stainless Steel Distribution Box with molded cable, Top-Mount, 8 Port
Ultra-Lock, 5.0m Cable, IP69K

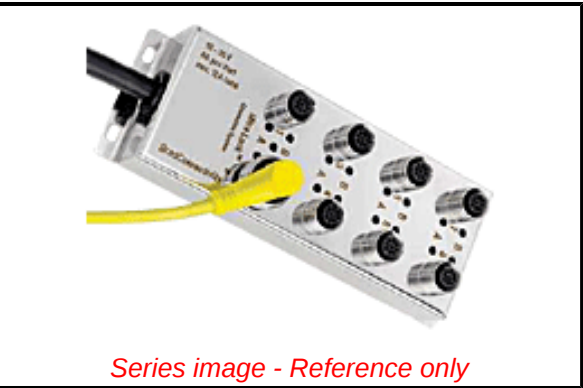

Series image - Reference only

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Passive Distribution Boxes
Series	120119
Comments	PNP SENSORS
IP Rating	IP69K
NEMA Rating	NEMA 6
Overview	Brad Ultra-Lock Connection System
Product Name	Ultra-Lock (M12)
UPC	887191061917

Physical	
Bus I/O	Ultra-Lock (M12)
Cable Connector Orientation	Straight
Cable Length	5.0m
Home Run Cable Length	10.0m
Home Run Connector	N/A
Home Run Interface	Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Housing	Steel
Material - Metal	Brass
Material - Plating Mating	Nickel
Orientation	Top-Mount
Poles	5
Poles (wired)	4
Ports	8
Temperature Range - Operating	-5°C to +80°C
Wiring Configuration	Dual I/O per Port

Electrical	
Current - Maximum per Contact	12.0A per module, 4.0A per port
Functional Wiring	Parallel
Voltage - Maximum	10-30V DC

Material Info	
Engineering Number	BTS805P-FSE-05

Reference - Drawing Numbers	
Sales Drawing	1201190042-000

EU ELV
Not Relevant

EU RoHS
Not Reviewed
REACH SVHC
Not Reviewed
Halogen-Free
Status
Not Reviewed

China RoHS

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[120119 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION