

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1210230238](#)

**Status:** **Active**

**Overview:** mPm DIN Valve Connectors

**Description:** mPm DIN Valve Connector, Form A-18mm, PG9 Internal Threads, 2 Pole Plus Ground Terminal, 250V AC/300V DC, Black, NBR Profiled Gasket and Screw, Bulk Pack, Mounted


**Documents:**

[Drawing \(PDF\)](#)

[Product Specification STR-1552-001 \(PDF\)](#)

[Packaging Specification PK-121023-C18-001 \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

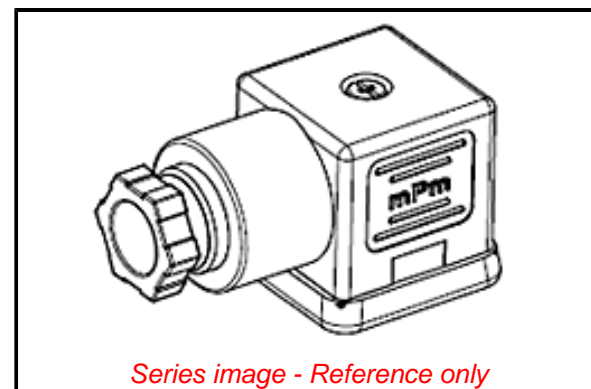

*Series image - Reference only*

**General**

Product Family	Field Attachable / Accessories
Series	<a href="#">121023</a>
Form	A - 18mm
IP Rating	IP65
Material - Contact	Brass
Overview	<a href="#">mPm DIN Valve Connectors</a>
Product Name	mPm
Type	Field Attachable Connector
UPC	883906248925

**Physical**

Cable Diameter	6.00-8.00mm
Coupling Type	Internal Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	N/A
Keyway	None
Material - Connector Body	Polyamide
Material - Coupling Nut	N/A
Material - Plating Mating	Silver
Net Weight	24.040/g
Orientation	90° Angle
Pitch - Mating Interface	18.00mm
Poles	2
Temperature Range - Operating	-40°C to +90°C
Wire Size AWG	16

**Electrical**

Current - Maximum per Contact	16.0A
Voltage - Maximum	250V AC / 300V DC

**Material Info**

Engineering Number	C18209N21
--------------------	-----------

**Reference - Drawing Numbers**

Packaging Specification	PK-121023-C18-001
Product Specification	STR-1552-001
Sales Drawing	1210230229-000, SD-121023-001-001

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Contained Per - D(2020)9139-DC (19 Jan 2021)

Lead

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

50 Image

Not Relevant

Not Contained

**Search Parts in this Series**

[121023 Series](#)