

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300138078](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change Receptacle, 5 Poles, 1/2" - 14 NPT Threads, Male (Straight) to 16 AWG Leads, 1.0m (3.28') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Industrial Receptacles
Series [130013](#)
IP Rating IP67
Overview [Brad Mini-Change Connectors](#)
Product Name Mini-Change
Type Single Ended (pigtail)
UPC 887191262673

Physical

Coupling Type External Thread
Gender Male
Keyway Single
Length 1.0m
Material - Component Zinc Die-Cast with Black Epoxy
Mounting Thread Size 1/2" - 14 NPT
Net Weight 137.532/g
Orientation Straight
Panel Mount N/A
Poles 5
Temperature Range - Operating -20°C to +105°C
Wire Size AWG 16
Wire/Cable Type UL 1015

Electrical


Current - Maximum per Contact 8.0A
Voltage - Maximum 300V AC/DC

Material Info

Engineering Number 1R5006A80M010

Reference - Drawing Numbers

Sales Drawing SD-130013-039

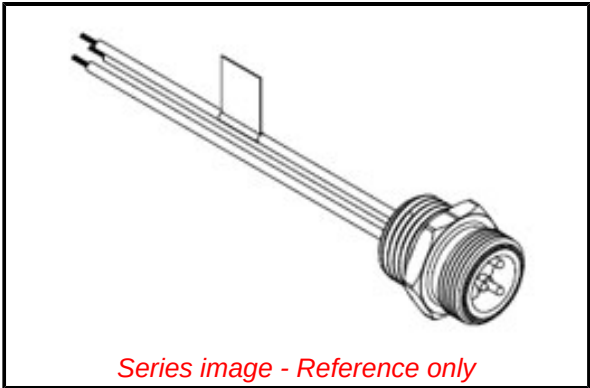

Series image - Reference only

EU ELV

Compliant with Exemption 3

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)
lead

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Not Relevant

Compliant with
Exemption 3

Not Contained

Search Parts in this Series

[130013](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION