


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300170029](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change Field Attachable, Male Connector, 5 Pole, Cable Range: 5.08-11.43mm Outside Diameter with External Threads

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	LR6837
General	
Product Family	Field Attachable / Accessories
Series	130017
Approvals	cCSAus certified
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Type	Field Attachable Connector
UPC	78172553065
Physical	
Cable Diameter	5.08-11.43mm (.200-.450")
Coupling Type	External Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Male
Keyway	Single
Material - Connector Body	Nylon
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	59.874/g
Orientation	Straight
Poles	5
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	15 to 24
Electrical	
Current - Maximum per Contact	8.0A
Voltage - Maximum	600V AC/DC
Material Info	
Engineering Number	1A5006-34
Reference - Drawing Numbers	
Sales Drawing	SD-130017-009-001

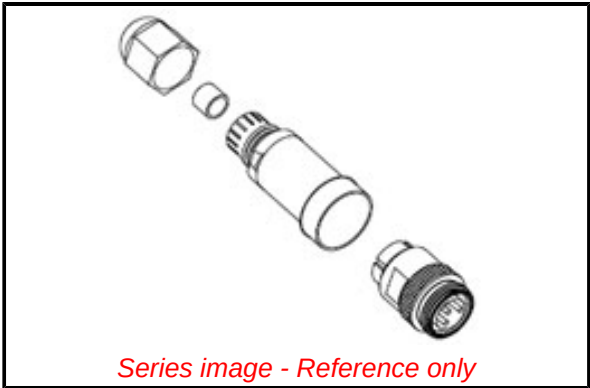

EU ELV Not Relevant	
EU RoHS Compliant with Exemption 6(c) REACH SVHC Contained Per - D(2020)9139-DC (19 Jan 2021) Lead Halogen-Free Status Not Low-Halogen For more information, please visit Contact US	China RoHS 50 Image Not Relevant Not Contained

Search Parts in this Series
[130017](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION