

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300170058

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change Field Attachable, Male Connector, 4 Pole, Cable Range: 5.08-12.19mm Outside Diameter with External Threads

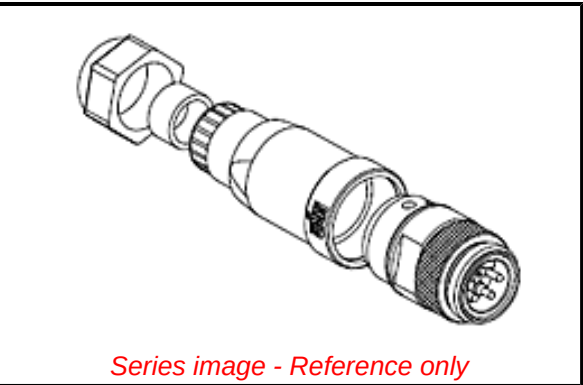

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E258922
General	
Product Family	Field Attachable / Accessories
Series	130017
Approvals	cULus Listed
IP Rating	IP67
Material - Contact	Brass
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Type	Field Attachable Connector
UPC	887191426433
Physical	
Cable Diameter	5.00 - 12.00mm (.197-.472")
Coupling Type	External Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Male
Keyway	Single
Material - Connector Body	Nylon
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	57.152/g
Orientation	Straight
Poles	4
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	15 to 24
Electrical	
Current - Maximum per Contact	15.0A
Voltage - Maximum	600V AC/DC
Material Info	
Engineering Number	1A4006-34PWR
Reference - Drawing Numbers	
Sales Drawing	SD-130017-017-001

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2020)9139-DC (19 Jan 2021)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

130017 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION