

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300390166

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change to Micro-Change (M12) Double-Ended Cordset, 5 Poles, Male (Straight) to Female (Straight), 22 AWG, DeviceNet Standard Cable Plus Drain, 5.0m (16.40') Length

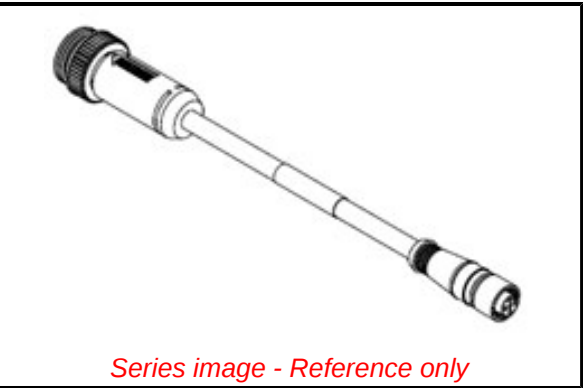

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Cordsets
Series	130039
Connector End A	Mini-Change
Connector End B	Micro-Change (M12)
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Mini-Change Connectors
Product Name	DeviceNet, Micro-Change (M12), Mini-Change
Region	Europe
Type	Double Ended
UPC	78678801120
Physical	
Cable Diameter	6.86mm (.270")
Cable Length	5.0m (16.40')
Color - Cable Jacket	Gray
Coupling Style	Threaded
Gender	Female-Male
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PVC
Material - Coupling Nut	Die-Cast Zinc
Material - Plating Mating	Gold
Net Weight	180.000/g
Orientation	Straight to Straight
Poles	5
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	22
Wire/Cable Type	Shielded-Twisted Pair
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC
Material Info	
Engineering Number	DND21A-M050
Reference - Drawing Numbers	
Sales Drawing	1300390155-00P, SD-130039-020-001

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2020)9139-DC (19 Jan 2021)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

130039 Series

This document was generated on 08/03/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION