

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300390302

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

DeviceNet Trunk Receptacle, 5 Poles, 1/2" - 14 NPT, Male (Straight) to Leads, 4.0m (13.12') Length

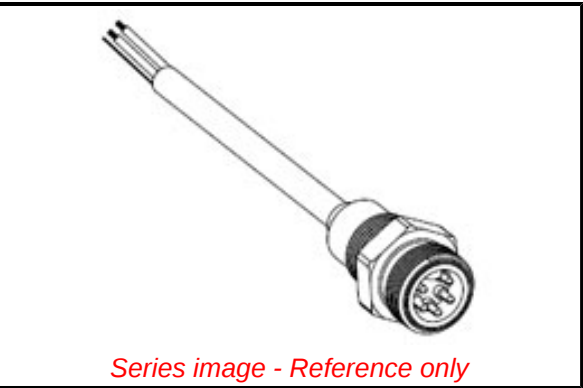

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Receptacles
Series	130039
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad Mini-Change Connectors
Product Name	DeviceNet Trunk
Type	Single Ended (pigtail)
UPC	78678847623
Physical	
Coupling Type	External Thread
Gender	Male
Keyway	Single
Length	4.0m
Material - Component	Gray Anodized Aluminum
Mounting Thread Size	1/2" - 14 NPT
Net Weight	425.000/g
Orientation	Straight
Panel Mount	N/A
Poles	5
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	18
Wire/Cable Type	Thick Standard Cable
Electrical	
Current - Maximum per Contact	8.0A
Voltage - Maximum	300V AC/DC
Material Info	
Engineering Number	DN5100-M040
Reference - Drawing Numbers	
Sales Drawing	SD-130039-001-001

EU ELV
Not Relevant

EU RoHS
Compliant with
Exemption 6(c),6(b)

China RoHS

REACH SVHC
Not Contained Per -
ED/108/2014 (17 Dec
2014)

Halogen-Free
Status
Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

130039 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION