

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300470037

Status:


Active

Overview:

Brad Micro-Change (M12) Connectors

Description:

Micro-Change (M12) PROFINET Field Attachable Connector, 4 Poles, D-Coded, Straight, Female, Shielded, Screw Termination, Cable Diameter 6.00-8.00mm

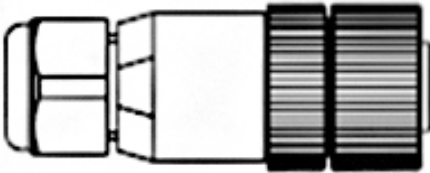

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Field Attachable / Accessories
Series	130047
Approvals	cCSAus certified
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Type	Field Attachable Connector
UPC	889056422055

Physical	
Cable Diameter	6.00-8.00mm (.236-.315")
Coupling Type	Internal Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Female
Keyway	D-coded
Material - Connector Body	Zinc Die-Cast
Material - Coupling Nut	Brass
Material - Plating Mating	Gold
Net Weight	2544.000/g
Orientation	Straight
Poles	4
Temperature Range - Operating	-40°C to +85°C
Wire Size AWG	18

Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V

Material Info	
Engineering Number	E1AS00-32

Reference - Drawing Numbers	
Sales Drawing	1300470037-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130047 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION