


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300680094](#)
Status: **Active**
Overview: BradPower Cordsets and Receptacles
Description: BradPower D-Size (1 3/8"–M35) 4-Pole Reducing Tee, with 4-Pole BradPower A-Size (7/8"–M22) Alternate Keyway Drop, Black

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
UL	E258922
General	
Product Family	Industrial Tees and Splitters
Series	130068
IP Rating	IP67
Overview	<u>BradPower Cordsets and Receptacles</u>
Product Name	BradPower D-Size
Type	Power Tap Tee
UPC	78172534044
Physical	
Drop Connector	BradPowerA-Size (7/8"–M22)
Drop Gender	Female
Keyway	Alternate
Left Trunk Connector	BradPower D-Size (1 3/8"–M35)
Left Trunk Gender	Female
Leg 1 Length	N/A
Leg 2 Length	N/A
Material - Cable Jacket	N/A
Material - Connector Body	PVC
Material - Coupling Nut	Anodized Aluminum
Net Weight	955.000/g
Poles	4
Right Trunk Connector	BradPower D-Size (1 3/8"–M35)
Right Trunk Gender	Male
Temperature Range - Operating	-20°C to +90°C
Electrical	
Current - Maximum per Contact	15.0A, 32.0A
Voltage - Maximum	600V AC/DC
Material Info	
Engineering Number	TC40141-200G
Reference - Drawing Numbers	
Sales Drawing	SD-130068-017-001

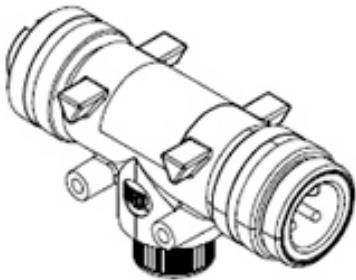

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant with Exemption 6(c) REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed For more information, please visit Contact US	China RoHS
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[130068](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION