

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0015311062](#)
Status: **Active**
Description: 4.80mm Pitch Wire-to-Wire Receptacle Housing, 6 Circuits, Natural

Documents:

3D Model	Product Specification PS-5025-002-001 (PDF)
3D Model (PDF)	Product Specification PS-5025-003-001 (PDF)
Drawing (PDF)	Packaging Specification SPK-5025-001-001 (PDF)
Product Specification PS-5025-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	5025
Application	Power, Wire-to-Wire
Product Name	N/A
UPC	800753642362

Physical


Circuits (maximum)	6
Color - Resin	Natural
Flammability	94V-2
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Nylon
Net Weight	2372.100/mg
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	4.80mm
Pitch - Termination Interface	4.80mm
Temperature Range - Operating	-40° to +105°C

Material Info

Engineering Number	5025-06R1
--------------------	-----------

Reference - Drawing Numbers

Packaging Specification	SPK-5025-001-001
Product Specification	PS-5025-001-001, PS-5025-002-001, PS-5025-003-001
Sales Drawing	SD-5025-06R1-001

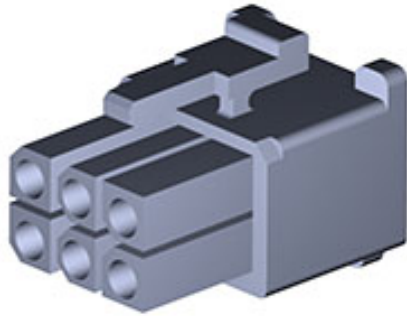

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[5025 Series](#)

Mates With

[15311061](#) , [15311063](#) Plug

Use With

[5005](#)