

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1727040070

Status:


Active

Overview:

FCT D-Sub Connectors

Description:

FCT Standard-Density D-Sub Connector, Female, Straight, Solder Cup, Gold Plating, 500 Mating Cycles, 25 Circuits

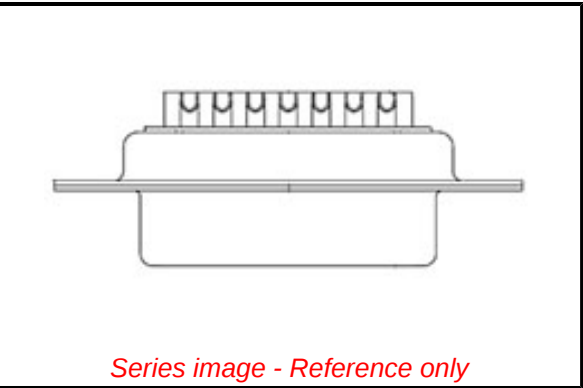

Documents:

Product Specification 1727040001-PS-000 (PDF)

Test Summary 1727040000-TS-000 (PDF)

Datasheet (PDF)

Brochure (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	D-Sub Products
Series	172704
IP Rating	IP20
Overview	FCT D-Sub Connectors
Product Category	D-Sub Connector
Product Name	FCT Products
Type	Standard Density
UPC	889056019811
Physical	
Circuits (Loaded)	25
Circuits (maximum)	25
Color - Resin	White
Durability (mating cycles max)	500
Gender	Female
Material - Contact	Copper Alloy
Material - Resin	PBT
Material - Shell	Steel
Net Weight	12.200/g
Number of Rows	2
Orientation	Straight
PCB Locator	No
PCB Retention	None
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Flange
Pitch - Mating Interface	2.84mm
Pitch - Termination Interface	2.84mm
Plating - Contact	Gold over Nickel
Plating - Shell	Tin
Polarized to Mating Part	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-55° to +125°C
Termination Style	Solder Cup
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20
Wire Size AWG	20
Electrical	
Current - Maximum per Contact	7.5A
Material Info	
Engineering Number	F25S0G1
Reference - Drawing Numbers	

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2020)9139-DC (19 Jan 2021)

lead

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

172704 Series

Mates With

FCT Standard-Density D-Sub, Size 3, 25 Position, Plug

This document was generated on 07/26/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION