

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1727040170](#)
Status: **Active**
Overview: [FCT D-Sub Connectors](#)
Description: FCT Standard-Density D-Sub Connector, Male, Straight, Solder Cup, Gold Plating, 200 Mating Cycles, 25 Circuits

Documents:

[Datasheet \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

| | |
|------------------|--------------------------------------|
| Product Family | D-Sub Products |
| Series | 172704 |
| IP Rating | IP20 |
| Overview | FCT D-Sub Connectors |
| Product Category | D-Sub Connector |
| Product Name | FCT Products |
| Type | Standard Density |
| UPC | 889056062466 |

Physical


| | |
|--------------------------------|------------------|
| Circuits (Loaded) | 25 |
| Circuits (maximum) | 25 |
| Color - Resin | White |
| Durability (mating cycles max) | 200 |
| Gender | Male |
| Material - Contact | Copper Alloy |
| Material - Resin | PBT |
| Material - Shell | Steel |
| Net Weight | 10.700/g |
| Number of Rows | 2 |
| Orientation | Straight |
| PCB Locator | No |
| PCB Retention | None |
| Packaging Type | Carton |
| Panel Mount | Rear |
| Panel Mount Method | Flange |
| Pitch - Mating Interface | 2.84mm |
| Pitch - Termination Interface | 2.84mm |
| Plating - Contact | Gold over Nickel |
| Plating - Shell | Tin |
| Polarized to Mating Part | Yes |
| Ports | 1 |
| Shielded | Yes |
| Temperature Range - Operating | -55° to +125°C |
| Termination Style | Solder Cup |
| Waterproof / Dustproof | No |
| Waterproof / Dustproof Type | IP20 |
| Wire Size AWG | 20 |

Electrical

| | |
|-------------------------------|------|
| Current - Maximum per Contact | 7.5A |
|-------------------------------|------|

Material Info

| | |
|--------------------|---------|
| Engineering Number | F25P0G2 |
|--------------------|---------|

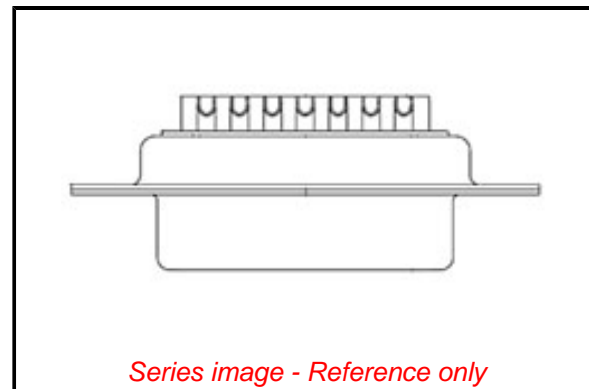

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)

Lead

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[172704 Series](#)

Mates With

FCT Standard-Density D-Sub, Size 3, 25 Position, Socket

This document was generated on 07/30/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION