

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190030020](#)
Status: **Active**
Overview: [Standard Quick-Disconnect Terminals](#)
Description: InsulKrimp Quick Disconnect, Female, for 18-22 (0.80-0.35mm²), Mylar Tape, Tab 4.75 x 0.81mm, Pink

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[3D Model \(PDF\)](#)
[Product Specification PS-19902-008-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)
[Product Specification PS-19902-015-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
CSA LR18689
UL E79133

General
Product Family Quick Disconnects
Series [19003](#)
Comments Funnel Entry
Crimp Quality Equipment Yes
Insulated Fully
Overview [Standard Quick-Disconnect Terminals](#)
Product Name InsulKrimp
Type Quick Disconnect
UPC 800753028708

Physical
Barrel Type Closed
Color - Resin Pink
Flammability 94V-2
Gender Female
Glow-Wire Capable No
Insulation Nylon (PA)
Lock to Mating Part None
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Nylon
Net Weight 0.907/g
Orientation Straight
Packaging Type Adhesive Tape on Reel
Plating min - Mating 4.064µm
Plating min - Termination 4.064µm
Polarized to Mating Part No
Tab Thickness 0.81mm
Tab Width 4.75mm
Temperature Range - Operating -65° to +105°C
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 3.43mm max.
Wire Size AWG 18, 20, 22

Electrical
Voltage - Maximum 600V

Solder Process Data
Lead-freeProcess Capability N/A

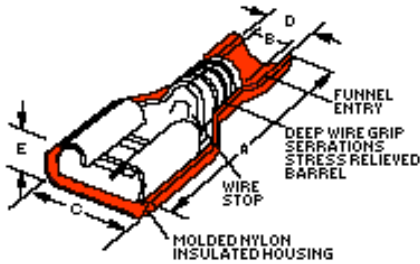

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
D(2020)9139-DC (19
Jan 2021)
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[19003 Series](#)

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	192880049
Mini-Mac Applicator	638857000

Engineering Number

AA-2203T

Product Specification

PS-19902-008-001, PS-19902-011-001,
PS-19902-015-001
SD-19003-005-001

Sales Drawing

This document was generated on 08/18/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION