

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0019092068](#)
Status: **Active**
Overview: [Standard .093" Pin and Socket Connectors](#)
Description: 2.36mm Diameter Standard .093" Pin and Socket Plug Housing with Positive Latch, UL 94V-2, with Panel Mount, 6 Circuits

Documents:
[3D Model](#)
[3D Model \(PDF\)](#)
[Drawing \(PDF\)](#)
[Product Specification PS-3191-001-001 \(PDF\)](#)
[Packaging Specification 31910002-PK-000 \(PDF\)](#)
[Packaging Specification PK-3191-001-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR19980
UL E29179

General
Product Family Crimp Housings
Series [3191](#)
Application Power, Wire-to-Wire
Comments Polarized to Mating Part, with Mounting Ears
Overview [Standard .093" Pin and Socket Connectors](#)
Product Name Standard .093"
UPC 800753594227


Physical
Breakaway No
Circuits (maximum) 6
Circuits Detail 2x3
Color - Resin Natural
Flammability 94V-2
Gender Plug
Glow-Wire Capable No
Keying to Mating Part None
Lock to Mating Part Yes
Material - Resin Nylon
Net Weight 7.382/g
Number of Rows 2
Packaging Type Bag
Panel Mount Yes
Pitch - Mating Interface 6.70mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40° to +105°C

Electrical
Current - Maximum per Contact 9.0A

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number 3191-6P

Reference - Drawing Numbers
[Packaging Specification 31910002-PK-000, PK-3191-001-001](#)
[Product Specification PS-3191-001-001](#)
[Sales Drawing 31910600-SD-000](#)

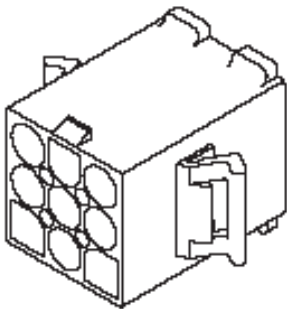

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
D(2020)9139-DC (19
Jan 2021)
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[3191 Series](#)

Mates With
[19091066](#) , [19091069](#) , [5219](#)

Use With
Standard .093" Female Crimp Terminals
[1189](#) , [1381](#) , [1433](#) , [4550](#) . Standard .093"
Male Crimp Terminals [1190](#) , [1380](#) , [1434](#) ,
[1973](#) , [42138](#)

This document was generated on 08/23/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION