

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0022552282](#)
Status: **Active**
Overview: [SL Modular Connectors](#)
Description: 2.54mm Pitch SL Crimp Housing, Dual Row, Version B, Polarized, 28 Circuits, Black

Documents:

3D Model	Product Specification PS-70400-001 (PDF)
Drawing (PDF)	Test Summary TS-70058-001-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	70450
Application	Signal, Wire-to-Board
Comments	Version B
Overview	SL Modular Connectors
Product Name	SL
UPC	800754397346

Physical

Breakaway	No
Circuits (maximum)	28
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Polyester
Net Weight	2.410/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	No
Temperature Range - Operating	-40° to +105°C

Solder Process Data


Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Engineering Number	704500062
--------------------	-----------

Reference - Drawing Numbers

Product Specification	PS-70400-001
Sales Drawing	SD-70450-0050-0075-0
Test Summary	TS-70058-001-001

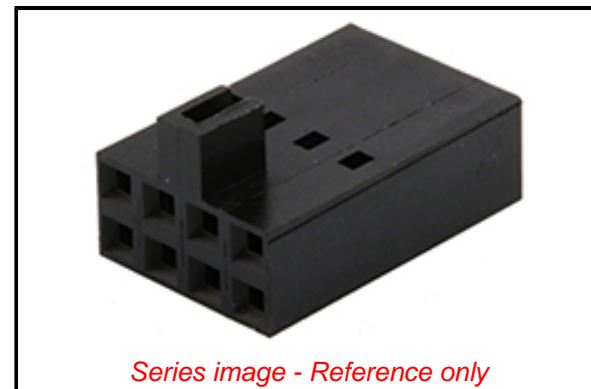

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[70450 Series](#)

Mates With

2.54mm Pitch C-Grid Header [70229](#) , [70280](#)
 , [70246](#) , [70247](#)

Use With

[70058](#) , [71851](#)