

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0029110033](#)
Status: **Active**
Overview: [Mini-Latch Wire-to-Board / Wire-to-Wire Connector System](#)
Description: 2.50mm Pitch Mini-Latch Wire-to-Wire Plug Housing, Friction Lock, without Mounting Ears, 3 Circuits, Natural

Documents:

3D Model	Product Specification PS-51191-003-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Drawing (PDF)	

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	5240
Application	Signal, Wire-to-Wire
Overview	Mini-Latch Wire-to-Board / Wire-to-Wire Connector System
Product Name	Mini-Latch
UPC	800753627802

Physical


Circuits (maximum)	3
Color - Resin	Natural (White)
Flammability	94V-0
Gender	Plug
Glow-Wire Capable	No
Lock to Mating Part	Yes
Net Weight	567.800/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	2.50mm
Stackable	No
Temperature Range - Operating	-40° to +105°C

Material Info

Engineering Number	5240-031
--------------------	----------

Reference - Drawing Numbers

Product Specification	PS-51191-003-001
Sales Drawing	SD-5240-N1-001

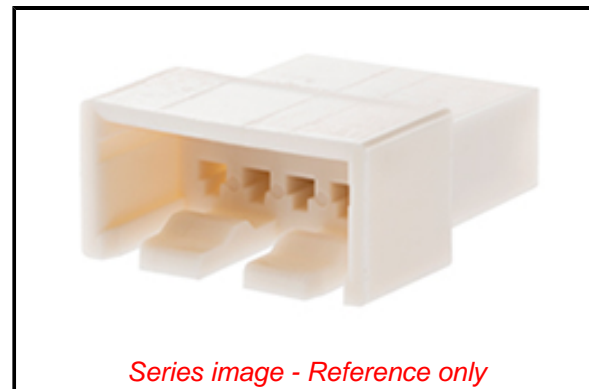

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[5240 Series](#)

Mates With

[51191 Housing](#)

Use With

[5241](#)