

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0347290202

Status:


Active

Overview:

Stac64 Single, Multi-Pocket and Hybrid Header System

Description:

Stac64 Receptacle Housing, 20 Circuits, Dual Row, Polarization C, Brown, Tray

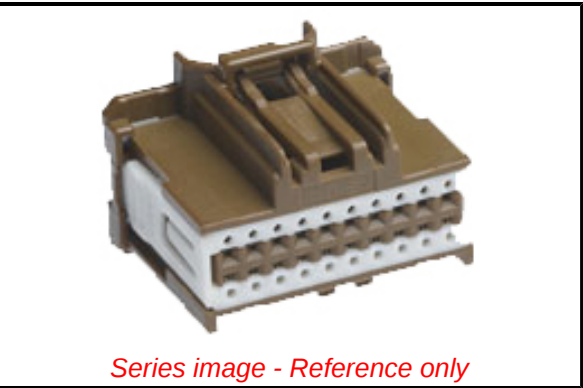

|                                                                     |                                                                  |
|---------------------------------------------------------------------|------------------------------------------------------------------|
| Documents:                                                          |                                                                  |
| <a href="#">Drawing (PDF)</a>                                       | <a href="#">Application Specification AS-34729-020-001 (PDF)</a> |
| <a href="#">3D Model (PDF)</a>                                      | <a href="#">Packaging Specification PK-31301-201-001 (PDF)</a>   |
| <a href="#">3D Model</a>                                            | <a href="#">Brochure (PDF)</a>                                   |
| <a href="#">Product Specification PS-34729-020-001 (PDF)</a>        | <a href="#">RoHS Certificate of Compliance (PDF)</a>             |
| <a href="#">Application Specification 347290200-AS-CH-000 (PDF)</a> |                                                                  |

|                               |                                                      |
|-------------------------------|------------------------------------------------------|
| General                       |                                                      |
| Product Family                | Crimp Housings                                       |
| Series                        | 34729                                                |
| Application                   | Automotive, Signal, Wire-to-Board                    |
| Overview                      | Stac64 Single, Multi-Pocket and Hybrid Header System |
| Polarization                  | C                                                    |
| Product Name                  | Stac64                                               |
| UPC                           | 884982006560                                         |
| Physical                      |                                                      |
| Circuits (maximum)            | 20                                                   |
| Color - Resin                 | Brown                                                |
| Gender                        | Receptacle                                           |
| Glow-Wire Capable             | No                                                   |
| Keying to Mating Part         | None                                                 |
| Lock to Mating Part           | Yes                                                  |
| Material - Resin              | High Temperature Thermoplastic                       |
| Net Weight                    | 7.530/g                                              |
| Number of Rows                | 2                                                    |
| Packaging Type                | Tray                                                 |
| Panel Mount                   | N/A                                                  |
| Pitch - Mating Interface      | 2.54mm                                               |
| Pitch - Termination Interface | 2.54mm                                               |
| Polarized to Mating Part      | Yes                                                  |
| Stackable                     | Yes                                                  |
| Temperature Range - Operating | -40° to +100°C                                       |
| Electrical                    |                                                      |
| Current - Maximum per Contact | 10.0A                                                |
| Solder Process Data           |                                                      |
| Lead-freeProcess Capability   | N/A                                                  |
| Material Info                 |                                                      |
| Reference - Drawing Numbers   |                                                      |
| Application Specification     | 347290200-AS-CH-000, AS-34729-020-001                |
| Packaging Specification       | PK-31301-201-001                                     |
| Product Specification         | PS-34729-020-001                                     |
| Sales Drawing                 | SD-34729-020                                         |

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2020)9139-DC (19 Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

Green Image

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series  
34729 Series

Mates With  
34690 2.54mm Pitch Stac64 Vertical Header, 34691 2.54mm Pitch Stac64 Right Angle Header

Use With  
34803 CTX64 Female Terminal