

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0348240245](#)
Status: **Active**
Overview: [Mini50 Connection Systems](#)
Description: Mini50 Unsealed Receptacle, Dual Row, Non-Bridged, 24 Circuits, EcoPaXX Resin, Polarization Option B, Gray


Documents:
[3D Model](#) [Application Specification AS-34791-020-CH-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [Test Summary 347910020-TS-000 \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-34791-020-001 \(PDF\)](#) [Product Literature \(PDF\)](#)
[Application Specification AS-34791-020-001 \(PDF\)](#)

General	
Product Family	Crimp Housings
Series	34824
Application	Automotive, Power, Wire-to-Board
Overview	Mini50 Connection Systems
Polarization	B
Product Name	Mini50
UPC	191128224826

Physical	
Circuits (maximum)	24
Color - Resin	Gray
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	2.376/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Pitch - Termination Interface	2.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

Material Info

Reference - Drawing Numbers	
Application Specification	AS-34791-020-001, AS-34791-020-CH-001
Product Specification	PS-34791-020-001
Sales Drawing	SD-34824-002-001
Test Summary	347910020-TS-000

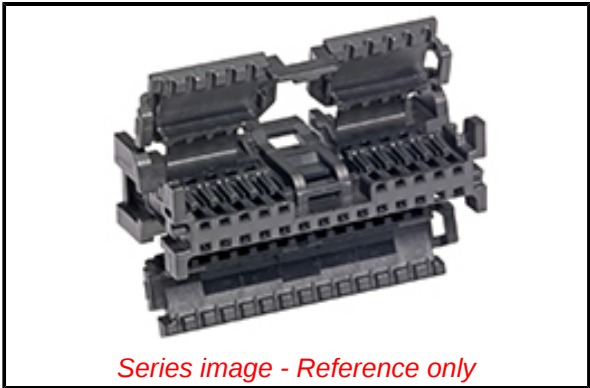

EU ELV
Compliant

EU RoHS Compliant REACH SVHC Not Contained Per - D(2020)9139-DC (19 Jan 2021) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Compliant Not Contained

Search Parts in this Series
[34824](#) Series

Mates With
Mini50 Vertical Headers [34825](#) , Mini50
Right-Angle Through Hole Header [34826](#) ,
Mini50 Right-Angle Surface Mount Header
[34897](#)

Use With
CTX50 Unsealed Terminals [560023](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION