

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0349590340

Status:


Active

Overview:

Mini50 Connection Systems

Description:

Mini50 Unsealed Receptacle, 3 Rows, with CPA, 34 Circuits, Polarization Option A, Black

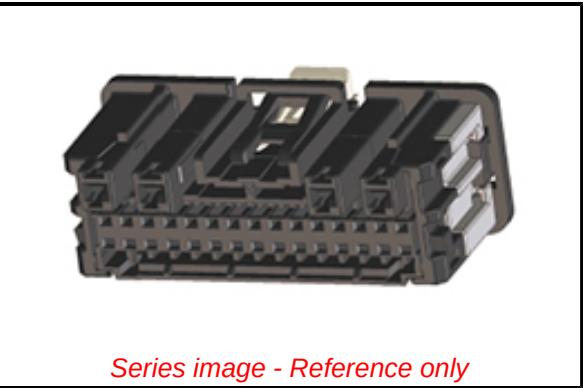

Documents:	
3D Model (PDF)	Application Specification AS-34959-001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-31301-538-001 (PDF)
3D Model	Test Summary TS-34961-001-001 (PDF)
Product Specification PS-34959-001-001 (PDF)	RoHS Certificate of Compliance (PDF)
Application Specification 349590001-AS-CH-000 (PDF)	Product Literature (PDF)

General	
Product Family	Crimp Housings
Series	34959
Application	Automotive, Power, Wire-to-Board
Overview	Mini50 Connection Systems
Polarization	A
Product Name	Mini50
UPC	887191704418
Physical	
Circuits (maximum)	34
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	5.524/g
Number of Rows	3
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Pitch - Termination Interface	2.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

Material Info	
Reference - Drawing Numbers	
Application Specification	349590001-AS-CH-000, AS-34959-001-001
Packaging Specification	PK-31301-538-001
Product Specification	PS-34959-001-001
Sales Drawing	SD-34959-030-001
Test Summary	TS-34961-001-001

EU ELV Compliant	
EU RoHS Compliant	China RoHS
REACH SVHC Not Contained Per - D(2020)9139-DC (19 Jan 2021)	
Halogen-Free Status Low-Halogen	
For more information, please visit Contact US	
China ROHS ELV	Green Image Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
34959 Series

Mates With
Mini50 Vertical Headers:
 349580340 , 349587340 , 349588340
Mini50 Right-Angle Headers:
 349610340 , 349617340 , 349618340

Use With
CTX50 Unsealed Terminals 560023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION