


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0367921201](#)  
**Status:** **Active**  
**Overview:** [MX120G Sealed Connectors](#)  
**Description:** MX120G Pitch Sealed Female Connector Assembly, Dual Row 12 Circuit, Black

**Documents:**

<a href="#">3D Model</a>	<a href="#">Application Specification AS-36783-001-001 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Packaging Specification PK-36783-002-001 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification PS-36783-001-001 (PDF)</a>	

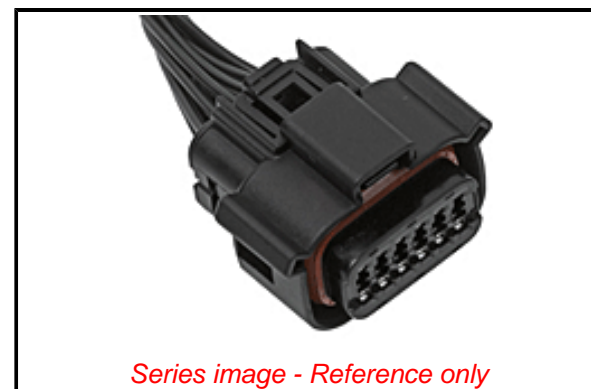

Series image - Reference only

**Agency Certification**

CSA	LR19980
UL	E29179

**General**

Product Family	Crimp Housings
Series	<a href="#">36792</a>
Application	Wire-to-Board
Overview	<a href="#">MX120G Sealed Connectors</a>
Product Name	MX120G
UPC	887191146799

**Physical**

Circuits (maximum)	12
Color - Resin	Black
Flammability	94HB
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	N/A
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	11.279/g
Number of Rows	2
Packaging Type	Carton
Panel Mount	No
Pitch - Mating Interface	3.20mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

**Electrical**

Current - Maximum per Contact	10.5A
-------------------------------	-------

**Solder Process Data**

Lead-free Process Capability	N/A
------------------------------	-----

**Material Info**

**Reference - Drawing Numbers**

Application Specification	AS-36783-001-001
Packaging Specification	PK-36783-002-001
Product Specification	PS-36783-001-001
Sales Drawing	SD-36792-001-001

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2020)9139-DC (19  
Jan 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[36792 Series](#)

**Use With**

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**