

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0430610012
Status: Active
Overview: SPOX Connector System
Description: 3.96mm Pitch SPOX Housing, 12 Circuits, Natural

Documents:
[3D Model](#) [Drawing \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR19980
UL E29179


General
Product Family Crimp Housings
Series 43061
Application Power, Wire-to-Board
Overview SPOX Connector System
Product Name SPOX
UPC 800753617131

Physical
Breakaway No
Circuits (maximum) 12
Circuits Detail 12
Color - Resin Natural
Flammability 94V-0
Gender Receptacle
Glow-Wire Capable No
Keying to Mating Part None
Lock to Mating Part Yes
Material - Resin Polyester
Net Weight 3.933/g
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 3.96mm
Pitch - Termination Interface 3.96mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating 0° to +75°C

Solder Process Data
Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers
Sales Drawing SD-43061

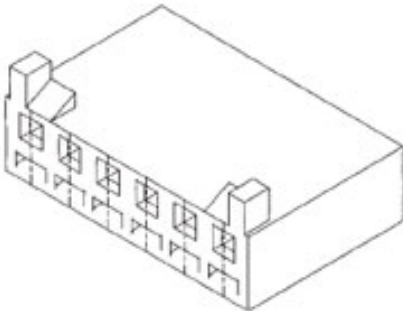

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - D(2020)9139-DC (19 Jan 2021) Halogen-Free Status Not Low-Halogen For more information, please visit Contact US	China RoHS China ROHS Green Image ELV Not Relevant RoHS Phthalates Not Contained
--	--

Search Parts in this Series
43061 Series

Mates With
3.96mm Pitch KK or SPOX headers

Use With
SPOX Terminal 5194 , 5225

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION