

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0436400400

Status:


Active

Overview:

Micro-Fit Connector System

Description:

Micro-Fit 3.0 Plug Housing, Single Row, 4 Circuits, UL 94V-0, Panel Mount Ears, Low-Halogen, Black

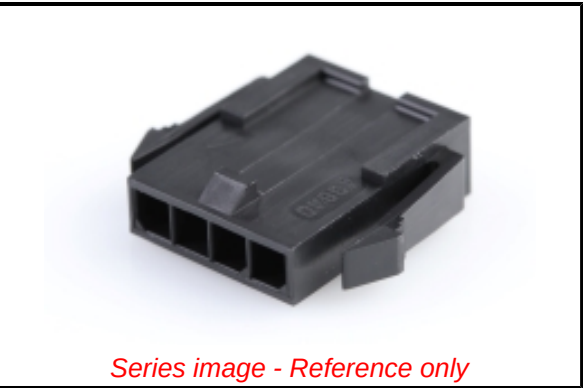

Series image - Reference only

Documents:

- Drawing (PDF)

3D Model

3D Model (PDF)

Product Specification 436500001-PS-JA-000 (PDF)

Product Specification 436500001-PS-KO-000 (PDF)

Product Specification 436500001-PS-SP-000 (PDF)

Product Specification PS-43650-001 (PDF)

Packaging Specification PK-43640-003-001 (PDF)
- Test Summary 430450005-TS-000 (PDF)

Test Summary TS-43045-001-001 (PDF)

Test Summary TS-43045-002-001 (PDF)

Test Summary TS-43045-003-001 (PDF)

Test Summary TS-46235-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Product Literature (PDF)

Agency Certification

CSA

UL

LR19980

E29179

General

Product Family

Series

Application

Overview

Product Name

UPC

Crimp Housings

43640

Power, Wire-to-Wire

Micro-Fit Connector System

Micro-Fit 3.0

800754366144

Physical

Circuits (maximum)

Color - Resin

Flammability

Gender

Glow-Wire Capable

Keying to Mating Part

Lock to Mating Part

Material - Resin

Net Weight

Number of Rows

Packaging Type

Panel Mount

Pitch - Mating Interface

Polarized to Mating Part

Stackable

Temperature Range - Operating

4

Black

94V-0

Plug

No

None

Yes

Nylon

0.836/g

1

Bag

Yes

3.00mm

Yes

No

-40° to +105°C

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Reference - Drawing Numbers

Packaging Specification

Product Specification

Sales Drawing

PK-43640-003-001

436500001-PS-JA-000, 436500001-PS-KO-000, 436500001-PS-SP-000, PS-43650-001

SD-43640-XXXX-001

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

43640 Series

Mates With

Micro-Fit 3.0 Receptacle Housing [43645](#)

Micro-Fit TPA Cable Assembly [145132](#)

Micro-Fit 3.0 Cable Assembly [214750](#) ,
[214751](#)

Use With

Micro-Fit 3.0 Crimp Terminals [43031](#)

Micro-Fit 3.0 Pre-Crimped Lead [214762](#) ,
[214763](#)

430450005-TS-000, TS-43045-001-001,
TS-43045-002-001, TS-43045-003-001,
TS-46235-001-001

This document was generated on 08/23/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION