


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0462350003**  
**Status:** **Active**  
**Overview:** Micro-Fit Connector System  
**Description:** Micro-Fit RMF Reduced Mating Force, Crimp Terminal, Female, with 0.38µm Selective Gold (Au) over Nickel (Ni), 26-30 AWG, without Lubricant

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Test Summary TS-46235-001-001 (PDF)</a>
<a href="#">Product Specification PS-46235-001-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Packaging Specification PK-46235-001-001 (PDF)</a>	<a href="#">Product Literature (PDF)</a>
<a href="#">Test Summary 430450006-TS-000 (PDF)</a>	

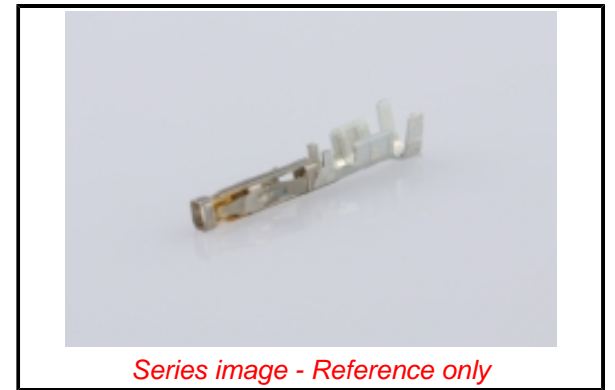

**General**

Product Family	Crimp Terminals
Series	46235
Application	Power, Wire-to-Board, Wire-to-Wire
Comments	Up to 50% reduction in mating force
Crimp Quality Equipment	Yes
Overview	<u>Micro-Fit Connector System</u>
Product Name	Micro-Fit RMF
UPC	800756683508

**Physical**

Durability (mating cycles max)	40
Gender	Female
Material - Metal	Copper-Zinc-Tin
Material - Plating Mating	Gold
Material - Plating Termination	Nickel
Net Weight	0.046/g
Packaging Type	Reel
Plating min - Mating	0.381µm
Plating min - Termination	1.270µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.27mm max.
Wire Size AWG	26, 28, 30
Wire Size mm <sup>2</sup>	N/A

**Electrical**

Current - Maximum per Contact	5.0A
-------------------------------	------

**Solder Process Data**

Lead-freeProcess Capability	N/A
-----------------------------	-----

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification	PK-46235-001-001
Product Specification	PS-46235-001-001
Sales Drawing	SD-46235-001-001
Test Summary	430450006-TS-000, TS-46235-001-001

**EU ELV**

**Compliant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Compliant

Not Contained

**Search Parts in this Series**

46235 Series

**Mates With**

43031 Micro-Fit 3.0 Male Crimp Terminals

**Use With**

43025 , 43645 Micro-Fit 3.0 Receptacle Housings, 44133 Micro-Fit BMI Panel Mount Receptacle Housings

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

**Description**

**Product #**

Extraction Tool for Micro-Fit Terminals PremiumGrade Hand Crimp Tool for Low Force Micro-Fit 3.0	<a href="#">11030043</a> <a href="#">638192900</a>
--	---

Terminals, 20-30 AWG	
FineAdjust for Low Force Crimp Terminal, 26-30 AWG Wire	<u>639001300</u>
T2 Terminator Tooling Die for Crimp Terminal, 26-30 AWG Wire	<u>639101300</u>

This document was generated on 08/24/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**