

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0501488100](#)
Status: **Active**
Overview: [Mizu Sealed Connectors](#)
Description: 2.50mm Pitch Mizu-P25 Crimp Terminal, 50148, Bag


- Documents:**
- [Drawing \(PDF\)](#)[Application Specification AS-52213-001-001 \(PDF\)](#)
- [Product Specification 522130000-PS-000 \(PDF\)](#)[Application Specification AS-52213-001-JP-001 \(PDF\)](#)
- [Product Specification PS-52213-003-001 \(PDF\)](#)[Packaging Specification PK-50148-003-001 \(PDF\)](#)
- [Application Specification 522130000-AS-000 \(PDF\)](#)[RoHS Certificate of Compliance \(PDF\)](#)
- [Application Specification AS-50147-001-001 \(PDF\)](#)

General	
Product Family	Crimp Terminals
Series	50148
Application	Signal, Wire-to-Wire
Crimp Quality Equipment	Yes
Overview	Mizu Sealed Connectors
Packaging Alternative	501488000 (Reel)
Product Name	Mizu-P25 Waterproof
UPC	800753347649
Physical	
Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	62.200/mg
Packaging Type	Bag
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.40-1.90mm
Wire Size AWG	20, 22
Wire Size mm²	N/A

Electrical	
Voltage - Maximum	125V
Solder Process Data	
Lead-freeProcess Capability	N/A

Material Info

Reference - Drawing Numbers	
Application Specification	522130000-AS-000, AS-50147-001-001, AS-52213-001-001, AS-52213-001-JP-001
Packaging Specification	PK-50148-003-001
Product Specification	522130000-PS-000, PS-52213-003-001
Sales Drawing	SD-50148-001-001

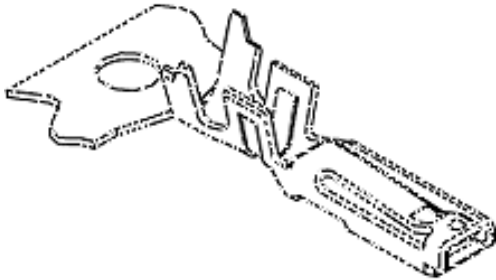

Series image - Reference only

EU ELV
Compliant

EU RoHS
Compliant
REACH SVHC
Not Contained Per -
D(2020)9139-DC (19
Jan 2021)
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China ROHS
ELV
RoHS Phthalates

Green Image
Compliant
Not Contained

Search Parts in this Series
50148 Series

Use With
Mizu-P25 2.50mm Pitch Waterproof
Receptacle Housing [52213](#)

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
PremiumGrade Hand Crimp Tool for 2.50mm Splash Proof Terminals, 20-22 AWG (AVSS and CAVS 0.50-0.30mm)	638118600
Extraction and Activation Tool	638132700

This document was generated on 07/28/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION