

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5019513000

Status:


Active

Overview:

Easy-On FFC FPC Connectors

Description:

Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 30 Circuits, Copper Alloy, Tin-Bismuth Plating

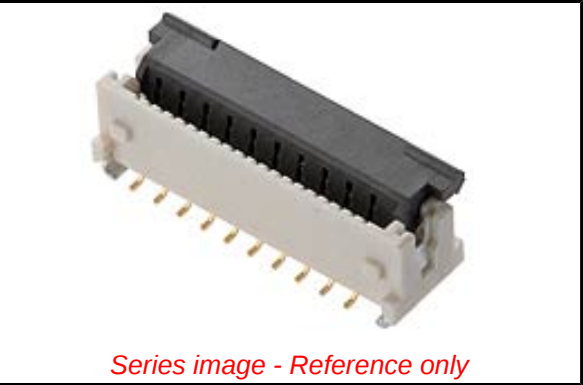

Series image - Reference only

Documents:	
3D Model	Datasheet (PDF)
3D Model (PDF)	Product Guide (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-501951-001-001 (PDF)	Reference Guide (PDF)
Packaging Specification 5019519200-201 (PDF)	

Agency Certification	
UL	E29179
General	
Product Family	FFC/FPC Connectors
Series	501951
Comments	Actuator Color is Brown
Overview	Easy-On FFC FPC Connectors
Product Name	Easy-On
Series Name	V-Flip
UPC	822350330749
Physical	
Actuator Type	Front Flip
Circuits (Loaded)	30
Color - Resin	White
Contact Position	N/A
Durability (mating cycles max)	20
Flammability	94V-0
Mated Height	4.05mm
Material - Metal	Copper Alloy
Material - Plating Mating	Tin-Bismuth
Material - Plating Termination	Tin-Bismuth
Material - Resin	Liquid Crystal Polymer
Net Weight	382.701/mg
Number of Rows	1
Orientation	Vertical
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Pitch - Termination Interface	0.50mm
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Polarized to PCB	No
Stackable	No
Surface Mount Compatible (SMC)	Yes
Temperature Range - Operating	-25° to +85°C
Wire/Cable Type	FFC/FPC
Electrical	
Current - Maximum per Contact	0.4A
Voltage - Maximum	50V

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)9139-DC (19 Jan 2021)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

501951 Series

Mates With

Premo-Flex FFC Cable [15166](#) , [98266](#) , [15266](#) , [15366](#)

Material Info

Reference - Drawing Numbers

Packaging Specification	5019519200-201
Product Specification	PS-501951-001-001
Sales Drawing	SD-501951-001-001, SD-501951-002-001

This document was generated on 08/17/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION