

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5022441530](#)
Status: **Active**
Overview: Easy-On FFC FPC Connectors
Description: 0.50mm Pitch Easy-On FFC/FPC Connector, For LVDS, 2.33mm Height, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 15 Circuits

Documents:
[3D Model \(PDF\)](#) [Product Specification PS-502244-001-001 \(PDF\)](#)
[3D Model](#) [Packaging Specification 5022449200-SPK-200 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family FFC/FPC Connectors
Series [502244](#)
Overview [Easy-On FFC FPC Connectors](#)
Product Name Easy-On
UPC 822350698825

Physical
Actuator Type Front Flip
Circuits (Loaded) 15
Color - Resin Black, Natural
Contact Position Bottom
Durability (mating cycles max) 20
Mated Height 2.33mm
Material - Metal Phosphor Bronze
Material - Plating Mating Gold
Material - Plating Termination Gold
Net Weight 183.496/mg
Number of Rows 1
Orientation Right Angle
PCB Locator No
PCB Mounting Surface Mount
PCB Retention Yes
Packaging Type Embossed Tape on Reel
Pitch - Mating Interface 0.50mm
Polarized to PCB Yes
Stackable No
Temperature Range - Operating -25° to +85°C
Wire/Cable Type FFC/FPC

Electrical
Current - Maximum per Contact 0.4A
Voltage - Maximum 50V

Material Info

Reference - Drawing Numbers
Packaging Specification 5022449200-SPK-200
Product Specification PS-502244-001-001
Sales Drawing SD-502244-001-001, SD-502244-002-001

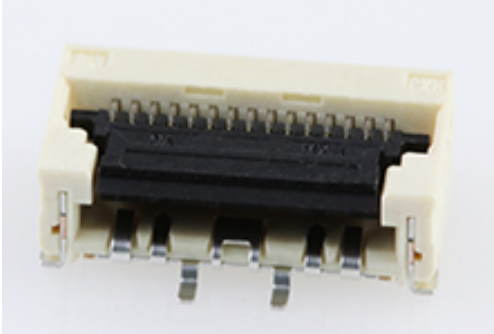

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)9139-DC (19 Jan 2021)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[502244 Series](#)

Mates With
Premo-Flex LVDS Cable [15021](#)