

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5022443330](#)
Status: **Active**
Overview: [Easy-On FFC FPC Connectors](#)
Description: 0.50mm Pitch Easy-On FFC/FPC Connector, For LVDS, 2.33mm Height, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 33 Circuits

Documents:

3D Model	Product Specification PS-502244-001-001 (PDF)
Drawing (PDF)	Packaging Specification 5022449200-SPK-200 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	FFC/FPC Connectors
Series	502244
Overview	Easy-On FFC FPC Connectors
Product Name	Easy-On
UPC	822350698818

Physical

Actuator Type	Front Flip
Circuits (Loaded)	33
Color - Resin	Black, Natural
Contact Position	Bottom
Durability (mating cycles max)	20
Mated Height	2.33mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	340.810/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-25° to +85°C
Wire/Cable Type	FFC/FPC


Electrical

Current - Maximum per Contact	0.4A
Voltage - Maximum	50V

Material Info

Reference - Drawing Numbers

Packaging Specification	5022449200-SPK-200
Product Specification	PS-502244-001-001
Sales Drawing	SD-502244-001-001, SD-502244-002-001

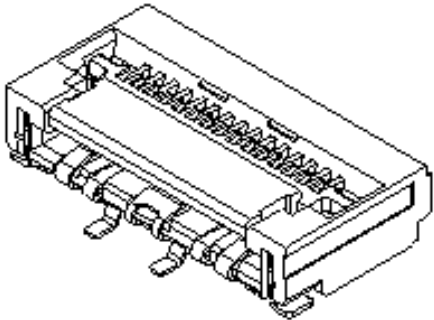

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[502244](#) Series

Mates With

Premo-Flex LVDS Cable [15021](#)