

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0050579303

Status:


Active

Overview:

SL Modular Connectors

Description:

SL Crimp Housing, Single Row, Version D, Back Ribs, 3 Circuits, Black

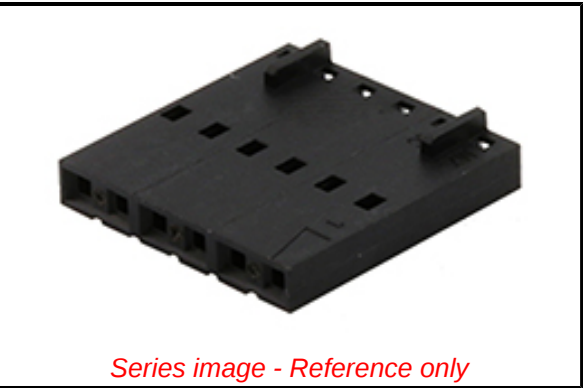

Documents:	
3D Model	Product Specification PS-71851-001 (PDF)
Drawing (PDF)	Packaging Specification PK-70066-100-001 (PDF)
3D Model (PDF)	Test Summary TS-70058-001-001 (PDF)
Product Specification PS-70058-001 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-70400-001 (PDF)	

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	70066
Application	Signal, Wire-to-Board
Comments	Version D
Overview	SL Modular Connectors
Product Name	SL
UPC	800753724815
Physical	
Circuits (maximum)	3
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	No
Material - Resin	Polyester Alloy
Net Weight	0.023/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	Yes
Temperature Range - Operating	-40° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	70066-0107
Reference - Drawing Numbers	
Packaging Specification	PK-70066-100-001
Product Specification	PS-70058-001, PS-70400-001, PS-71851-001
Sales Drawing	SD-70066-0106-0129-001
Test Summary	TS-70058-001-001

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

Green Image

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

70066 Series

Mates With

70004 Interim Clip, 70013 , 70022 , 70104 ,
70475 , 70431 , 70543 , 70553

Use With

SL Crimp Terminal 70021 , 70058 , 71851