

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0524651271

Status:


Active

Overview:

SlimStack Board-to-Board/Board-to-FPC Connectors

Description:

SlimStack Board-to-Board Connector, 0.80mm Pitch, Rigid Type Receptacle, 4.50 to 7.00mm Mated Height, Vertical, 12 Circuits, without Boss

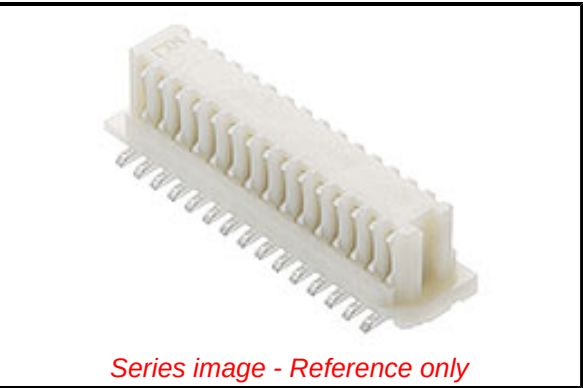

Series image - Reference only

Documents:	
3D Model	Packaging Specification SPK-52465-002-001 (PDF)
3D Model (PDF)	Datasheet (PDF)
Drawing (PDF)	Product Guide (PDF)
Product Specification PS-52465-010-001 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-52465-014-001 (PDF)	Reference Guide (PDF)
Product Specification PS-52465-015-001 (PDF)	

General	
Product Family	PCB Receptacles
Series	52465
Application	Board-to-Board, Signal
Overview	SlimStack Board-to-Board/Board-to-FPC Connectors
Product Name	SlimStack
Series Name	0.8 and above
UPC	822348142934
Physical	
Circuits (Loaded)	12
Circuits (maximum)	12
Color - Resin	Natural
Durability (mating cycles max)	30
Glow-Wire Capable	No
Mated Height	4.50mm, 5.65mm, 6.00mm, 7.00mm
Mated Width	4.70mm, 5.10mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	128.500/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	No
PCB Retention	None
PCB Thickness - Recommended	1.60mm
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.80mm
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Polarized to PCB	No
Surface Mount Compatible (SMC)	N/A
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount
Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	50V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	SPK-52465-002-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)9139-DC (19 Jan 2021)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

52465 Series

Mates With

53364 , 53353 , 53307 , 53309

Product Specification

Sales Drawing

PS-52465-010-001, PS-52465-014-001,
PS-52465-015-001
SD-52465-028, SD-52465-028-001, SD-52465-029-001

This document was generated on 07/28/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION