

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0527930670

Status:

Active

Overview:


Easy-On FFC FPC Connectors

Description:

1.00mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Right-Angle, Non-ZIF, Top Contact Style, 6 Circuits

Documents:	
Drawing (PDF)	Product Specification PS-52793-014-001 (PDF)
3D Model	Packaging Specification SPK-52793-001-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	FFC/FPC Connectors
Series	52793
Overview	Easy-On FFC FPC Connectors
Product Name	Easy-On
UPC	822348275311
Physical	
Actuator Type	Non-ZIF
Circuits (Loaded)	6
Color - Resin	Natural
Contact Position	Top
Durability (mating cycles max)	10
Flammability	94V-0
Mated Height	3.10mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin-Bismuth
Material - Plating Termination	Tin-Bismuth
Material - Resin	High Temperature Thermoplastic
Net Weight	257.395/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	1.00mm
Pitch - Termination Interface	1.00mm
Polarized to PCB	No
Stackable	No
Temperature Range - Operating	-20° to +85°C
Wire/Cable Type	FFC/FPC
Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	50V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	SPK-52793-001-001
Product Specification	PS-52793-014-001
Sales Drawing	527930000-000, 527931000-000

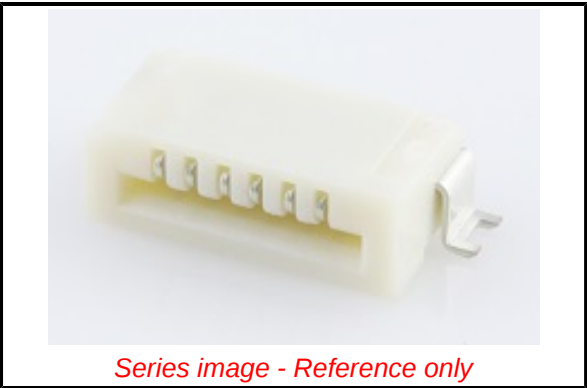

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)9139-DC (19 Jan 2021)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

52793 Series

This document was generated on 08/12/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION