

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0534600639

Status:


Active

Overview:

2.00mm I/O Connectors

Description:

2.00mm Pitch IEEE 1394-1995 Shielded I/O PCB Socket, Right-Angle, Upright, with Kinked Solder Tabs, Reflow Dip, 6 Circuits

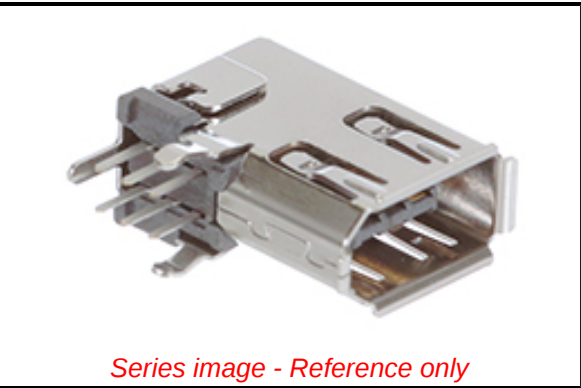

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification 534600000-000 (PDF)

Packaging Specification 534609200-SPK-200 (PDF)

RoHS Certificate of Compliance (PDF)

Product Literature (PDF)

Agency Certification		
UL		E29179
General		
Product Family		I/O Connectors
Series		53460
Application		Wire-to-Board
Component Type		Receptacle
Overview		2.00mm I/O Connectors
Product Name		2.00mm I/O Connectors
Type		N/A
UPC		191128445184
Physical		
Boot Color		N/A
Circuits (Loaded)		6
Circuits (maximum)		6
Color - Resin		Black
Flammability		94V-0
Gender		Female
Lock to Mating Part		Yes
Material - Metal		Brass
Material - Plating Mating		Gold
Material - Plating Termination		Tin
Material - Resin		High Temperature Thermoplastic
Net Weight		3223.521/mg
Number of Rows		2
Orientation		Right Angle
PC Tail Length		3.00mm
PCB Locator		Yes
PCB Retention		Yes
PCB Thickness - Recommended		1.60mm
Packaging Type		Tray
Panel Mount		No
Pitch - Mating Interface		2.00mm
Pitch - Termination Interface		2.00mm
Plating min - Mating		0.762µm
Plating min - Termination		1.000µm
Polarized to Mating Part		Yes
Polarized to PCB		Yes
Ports		1
Surface Mount Compatible (SMC)		Yes
Temperature Range - Operating		-40° to +85°C
Termination Interface: Style		Through Hole
Waterproof / Dustproof		No

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)9139-DC (19 Jan 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

53460 Series

Mates With

Serial I/O Connectors [551000670](#) , [551000680](#) , [5006540609](#)

Electrical

Current - Maximum per Contact	1.5A
Shield Type	Full Shield
Shielded	Yes
Voltage - Maximum	125V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Packaging Specification	534609200-SPK-200
Product Specification	534600000-000
Sales Drawing	534600000-001

This document was generated on 08/24/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION