

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0559090374

Status:


Active

Overview:

SlimStack Board-to-Board/Board-to-FPC Connectors

Description:

SlimStack Board-to-Board Plug, 0.40mm Pitch, J-Bend Series, 0.20µm Gold (Au) Plating, 1.50 or 1.80mm Mated Height, 3.40 or 4.20mm Mated Width, 30 Circuits

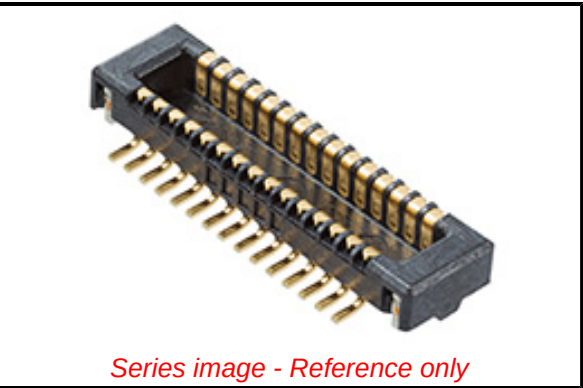

Documents:	
2D Drawing DXF (PDF)	Datasheet (PDF)
Drawing (PDF)	Product Guide (PDF)
3D Model	RoHS Certificate of Compliance (PDF)
2D Drawing (DXF)	Reference Guide (PDF)
3D Model (PDF)	

General	
Product Family	PCB Headers
Series	55909
Application	Board-to-Board, Signal
Comments	Solder Tab Plating: Tin
Overview	SlimStack Board-to-Board/Board-to-FPC Connectors
Product Name	SlimStack
Series Name	0.4, J-Bend
UPC	822348176069
Physical	
Breakaway	No
Circuits (Loaded)	30
Circuits (maximum)	30
Color - Resin	Black
Durability (mating cycles max)	30
Glow-Wire Capable	No
Lock to Mating Part	Yes
Mated Height	1.50mm, 1.80mm
Mated Width	3.40mm, 4.20mm
Material - Metal	Brass
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	31.130/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.40mm
Pitch - Termination Interface	0.40mm
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount
Electrical	
Current - Maximum per Contact	0.3A
Voltage - Maximum	50V AC (RMS)/DC
Material Info	

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)9139-DC (19 Jan 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

55909 Series

Mates With

SlimStack J-Bend Receptacle [51338](#) , [500913](#)