

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0559320210

Status:


Active

Overview:

MicroClasp Wire-to-Board System

Description:

2.00mm Pitch MicroClasp Wire-to-Board Header, Single Row, Vertical, 2 Circuits, with PCB Locator

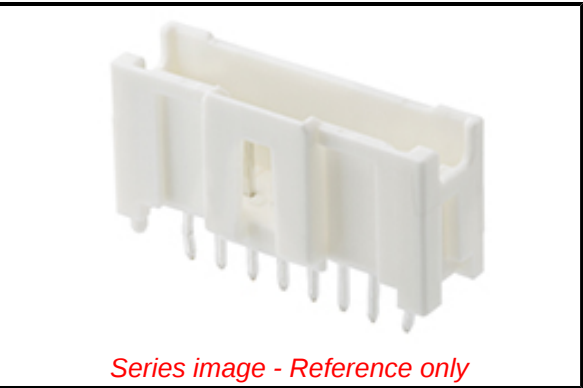

Series image - Reference only

Documents:

- [3D Model](#)
- [Drawing \(PDF\)](#)
- [3D Model \(PDF\)](#)
- [Product Specification 513820000-PS-001 \(PDF\)](#)
- [Product Specification PS-51382-004-001 \(PDF\)](#)
- [Application Specification 561340000-AS-000 \(PDF\)](#)
- [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL

E29179

General

Product Family

Series

Application

Overview

Product Name

UPC

PCB Headers

55932

Signal, Wire-to-Board

MicroClasp Wire-to-Board System

MicroClasp

800756631660

Physical

Breakaway

Circuits (Loaded)

Circuits (maximum)

Color - Resin

Durability (mating cycles max)

First Mate / Last Break

Glow-Wire Capable

Guide to Mating Part

Keying to Mating Part

Lock to Mating Part

Material - Plating Mating

Material - Plating Termination

Material - Resin

Net Weight

Number of Rows

Orientation

PC Tail Length

PCB Locator

PCB Retention

PCB Thickness - Recommended

Packaging Type

Pitch - Mating Interface

Shrouded

Stackable

Surface Mount Compatible (SMC)

Temperature Range - Operating

Termination Interface: Style

No

2

2

Natural

30

No

No

No

None

Yes

Tin

Tin

Polyester

343.800/mg

1

Vertical

3.20mm

Yes

Yes

1.60mm

Tray

2.00mm

Fully

No

No

-40° to +105°C

Through Hole

Electrical

Current - Maximum per Contact

Voltage - Maximum

3.0A

250V AC (RMS)/DC

Material Info

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

55932 Series

Mates With

MicroClasp Receptacle Housing [51382](#)

MicroClasp Cable Assembly [15136](#)

Reference - Drawing Numbers

Application Specification	561340000-AS-000
Product Specification	513820000-PS-001, PS-51382-004-001
Sales Drawing	SD-55932-002-001

This document was generated on 08/18/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION