

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5601230500

Status:


Active

Overview:

DuraClik Connector System

Description:

DuraClik ISL Wire-to-Board Receptacle Housing, Single Row, White, 5 Circuits

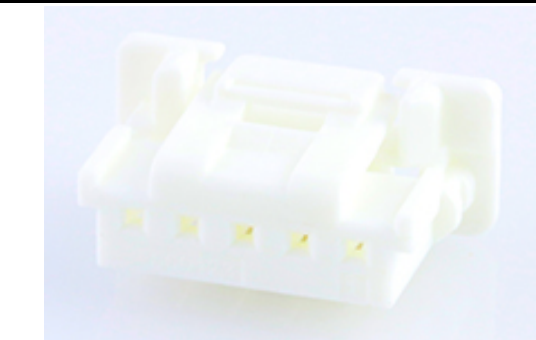

Series image - Reference only

Documents:	
3D Model (PDF)	Packaging Specification PK-560123-001-001 (PDF)
3D Model	Test Summary 5601230400-TS (PDF)
Drawing (PDF)	Test Summary 5601230600-TS (PDF)
Product Specification PS-560123-001-001 (PDF)	Datasheet (PDF)
Product Specification PS-560123-003-001 (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	560123
Application	Automotive, Signal, Wire-to-Board
Overview	DuraClik Connector System
Product Name	DuraClik
UPC	191128059114

Physical	
Circuits (maximum)	5
Color - Resin	White
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	0.316/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +130°C

Material Info

Reference - Drawing Numbers	
Packaging Specification	PK-560123-001-001
Product Specification	PS-560123-001-001, PS-560123-003-001
Sales Drawing	5601230500-005
Test Summary	5601230400-TS, 5601230600-TS

EU ELV
Compliant

EU RoHS Compliant REACH SVHC Not Contained Per - D(2020)9139-DC (19 Jan 2021) Halogen-Free Status Not Reviewed	China RoHS
--	-------------------

China ROHS ELV RoHS Phthalates	Green Image Compliant Not Contained
--------------------------------------	---

Search Parts in this Series
[560123](#) Series

Mates With
DuraClik Right-Angle Header [502352](#)

DuraClik Vertical Header [560020](#)

Use With
DuraClik ISL Terminal [560124](#)
DuraClik
ISL Retainer [5601250500](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION