

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0561618081**  
**Status:** **Active**  
**Overview:** DuraClik Connector System  
**Description:** 2.00mm Pitch DuraClik Crimp Terminal, Female, 22-26 AWG, Gold (Au) Plating, Reel

**Documents:**

[Drawing \(PDF\)](#) [Packaging Specification 561619200-200 \(PDF\)](#)  
[Product Specification PS-502351-002-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Application Specification AS-54992-006-001 \(PDF\)](#)

**General**

Product Family Crimp Terminals  
Series 56161  
Application Automotive, Signal, Wire-to-Board  
Crimp Quality Equipment Yes  
Overview DuraClik Connector System  
Packaging Alternative 561618181 (Bag)  
Product Name DuraClik  
UPC 800756476667

**Physical**

Gender Female  
Material - Metal Phosphor Bronze  
Material - Plating Mating Gold  
Material - Plating Termination Nickel  
Net Weight 18.300/mg  
Packaging Type Reel  
Termination Interface: Style Crimp or Compression  
Wire Insulation Diameter 1.40mm max.  
Wire Size AWG 22, 24, 26  
Wire Size mm<sup>2</sup> N/A


**Electrical**

Current - Maximum per Contact 3.0A  
Voltage - Maximum 125V

**Material Info**

**Reference - Drawing Numbers**

Application Specification AS-54992-006-001  
Application Tooling Documents 571753710ATS-000, 571753710ATS-J-000  
Crimp Specification CS-56161-003-001  
Packaging Specification 561619200-200  
Product Specification PS-502351-002-001  
Sales Drawing SD-56161-002-001

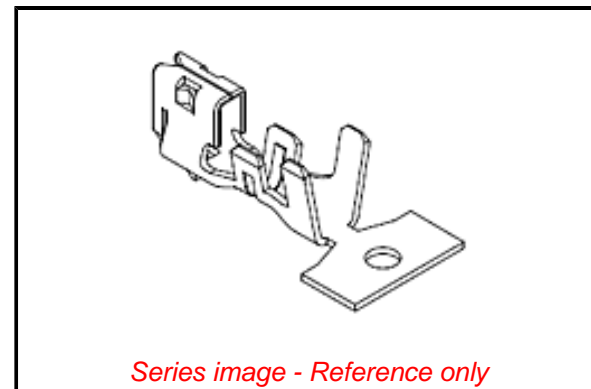

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

56161 Series

**Use With**

DuraClik Receptacle Housing 502351

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

Description	Product #
FineAdjust Applicator for 2.0 Wire-to-Board Crimp Receptacle Terminal and SMEC Crimp Receptacle Terminals, 22-26 AWG and AVSS 0.3 Wires	2037021900
PremiumGrade Hand Crimp Tool for Micro-Latch, DuraClik, and	638235100

Servo Motor Encoder  
Female Terminals,  
22-26 AWG  
T2 Terminator Die 638528000

**Japan**

**Description** **Product #**

Applicator for M211A 571753000

Bench Press, 22-30

AWG Wire

S-1 Applicator for 571753710

DuraClik and Mi II

Terminals, 22-26

AWG

This document was generated on 08/25/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**