

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0638119100](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: PremiumGrade Hand Crimp Tool for CP 0.635mm Female Terminals for CMC Connector, 0.22-0.35mm² Wire

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Application Tooling
Series	207129
Comments	Field Repair, See Tooling Specification (PDF) Above. Type: 7
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	PremiumGrade
Tool Type	Hand Crimp Tool
UPC	822350980487
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.


Physical

Net Weight 0.001/kg

Material Info

Reference - Drawing Numbers

Application Tooling Documents
ATS-638119100-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001

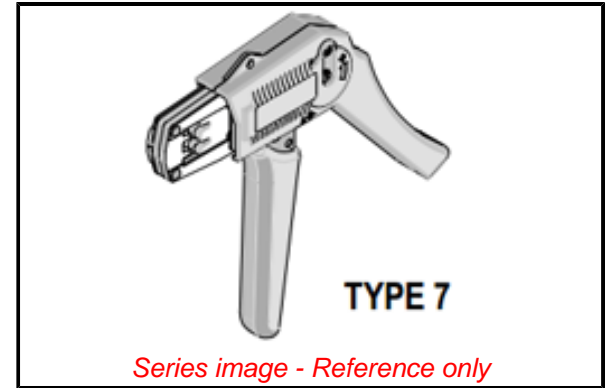

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Not Relevant

Not Relevant

Not Contained

Search Parts in this Series

207129 Series

Use With

Loose Piece Terminals

Application Tooling | FAQ

Description	Product #
--------------------	------------------

0.635mm CMC CP Female Terminal, Tin Plated, for Square	643221019
--	---------------------------

0.6mm x 0.6mm Pins, Wire Size 0.35mm²

0.635mm CMC CP Female Terminal, Tin Plated, Selective	643221229
---	---------------------------

1.27µm Gold in Contact Area, for Square 0.6mm x 0.6mm Pins, Wire Size 0.35mm²

0.635mm CMC CP Female Terminal, HP VERSION, Tin	643221349
---	---------------------------

Plated, Selective
1.27 μ m Gold in
Contact Area, for
Square 0.6mm x
0.6mm Pins, Wire
Size 0.35mm²

This document was generated on 07/31/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION