

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0638119200](#)  
**Status:** **Active**  
**Overview:** [Application Tooling](#)  
**Description:** PremiumGrade Hand Crimp Tool for CP 0.635mm Female Terminals for CMC connector, 0.50-0.75mm<sup>2</sup> Wire

**Documents:**  
[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Application Tooling
Series	207129
Comments	Field Repair, See Tooling Specification (PDF) Above. Type: 7
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	<a href="mailto:applicationtooling@molex.com">applicationtooling@molex.com</a>
Overview	<a href="#">Application Tooling</a>
Product Name	PremiumGrade
Tool Type	Hand Crimp Tool
UPC	822350980494
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.


**Physical**

Net Weight 0.001/kg

**Material Info**

**Reference - Drawing Numbers**

Application Tooling Documents  
 ATS-638119200-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001

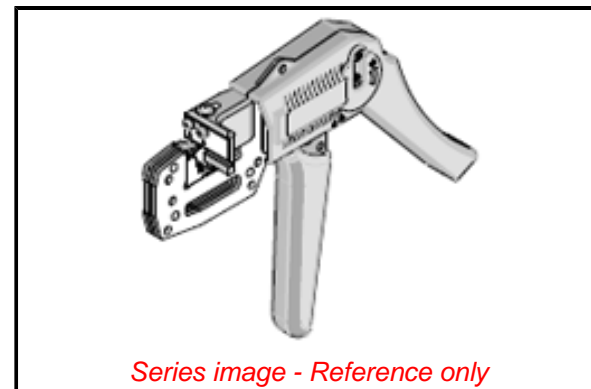

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per - ED/30/2017 (7 July 2017)

**Halogen-Free**

**Status**

**Not Relevant**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Not Relevant

Not Relevant

Not Contained

**Search Parts in this Series**

207129 Series

**Use With**

Loose Piece Terminals

**Application Tooling | FAQ**

Description	Product #
0.635mm CMC CP Female Terminal, Tin Plated, for Square Pins, Wire Size 0.6mm x 0.6mm 0.75mm <sup>2</sup>	<a href="#">643221029</a>
0.635mm CMC CP Female Terminal, Tin Plated, for Square Pins, Wire Size 0.6mm x 0.6mm 0.5mm <sup>2</sup>	<a href="#">643221039</a>
0.635mm CMC CP Female Terminal, Tin Plated, Selective 1.27µm Gold in Contact Area, for	<a href="#">643221219</a>

Square 0.6mm x  
0.6mm Pins, Wire  
Size 0.75mm<sup>2</sup>  
0.635mm CMC CP 643221239  
Female Terminal,  
Tin Plated, Selective  
1.27μm Gold in  
Contact Area, for  
Square 0.6mm x  
0.6mm Pins, Wire  
Size 0.5mm<sup>2</sup>  
0.635mm CMC CP 643221339  
Female Terminal,  
HP Version, Tin  
Plated, Selective  
1.27μm Gold in  
Contact Area, for  
Square 0.60mm x  
0.60mm Pins, Wire  
Size 0.75mm<sup>2</sup>  
0.635mm CMC CP 643221359  
Female Terminal,  
HP VERSION, Tin  
Plated, Selective  
1.27μm Gold in  
Contact Area, for  
Square 0.6mm x  
0.6mm Pins, Wire  
Size 0.5mm<sup>2</sup>

This document was generated on 07/27/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**