

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0638119700](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: Hand Crimp Tool for CP 2.8 Receptacle 14-16 AWG Type TXL Wire and >1.00-2.00mm² Type ID & ID Wire with 2.80mm, CMC Wire Seal Receptacle

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Application Tooling
Series	207129
Comments	Field Repair, See Tooling Specification (PDF) Above. Type: 4A
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	PremiumGrade
Tool Type	Hand Crimp Tool
UPC	883906191306
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.


Physical

Net Weight 428.885/zg

Material Info

Reference - Drawing Numbers

Application Tooling Documents [ATS-6381197HM-001](#)

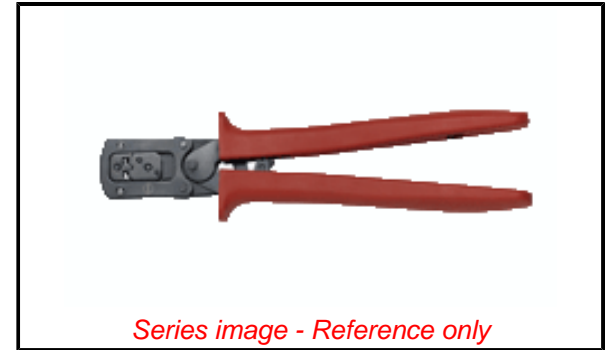

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Not Relevant

Not Relevant

Not Contained

Search Parts in this Series

[207129](#) Series

Use With

Battery Powered Crimping Tool [638160200](#), [638160250](#), Air Powered Crimping Tool [638160100](#)

Application Tooling

Description

FAQ

Product #

2.80mm, CMC CP [643241039](#)

Female Terminal, Tin plated, for Tab
Dimensions 2.80mm by 0.80mm, Wire Size > 1.00-2.00mm²

2.80mm, CMC CP [643241139](#)

Female Terminal, Tin plated; Selective
1.27µm Gold in Contact Area, for Tab
Dimensions 2.80mm by 0.80mm, Wire Size > 1.00-2.00mm²

This document was generated on 07/29/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION