

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0673298000](#)
Status: **Active**
Overview: [USB Products and Solutions](#)
Description: Universal Serial Bus (USB) Shielded I/O Receptacle, Type A, Single Upright Right-Angle, Solder Tail Length 2.00mm, Kinked Pins, PCB Thickness 1.20mm and 1.60mm, Gold (Au) Flash, Lead-Free

Documents:

[3D Model](#) [Packaging Specification PK-67329-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[3D Model \(PDF\)](#)

Agency Certification


UL E29179

General

Product Family I/O Connectors
 Series [67329](#)
 Application Wire-to-Board
 Comments Standard Mount Type
 Component Type Receptacle
 Overview [USB Products and Solutions](#)
 Product Name USB
 Standard USB 2.0
 Type A
 UPC 822350416887

Physical

Circuits (Loaded) 4
 Circuits (maximum) 4
 Color - Resin Black
 Flammability 94V-0
 Gender Female
 Lock to Mating Part Yes
 Material - Plating Mating Gold
 Material - Plating Termination Tin
 Mounting Style Upright
 Net Weight 2.025/g
 Number of Rows 4
 Orientation Right Angle
 PC Tail Length 2.00mm
 PCB Locator Yes
 PCB Retention Yes
 PCB Thickness - Recommended 1.60mm
 Packaging Type Tray
 Panel Mount No
 Pitch - Mating Interface N/A
 Pitch - Termination Interface 1.40mm
 Plating min - Mating 0.102µm
 Plating min - Termination 2.540µm
 Polarized to Mating Part Yes
 Polarized to PCB Yes
 Ports 1
 Surface Mount Compatible (SMC) Yes
 Termination Interface: Style Through Hole
 Waterproof / Dustproof No

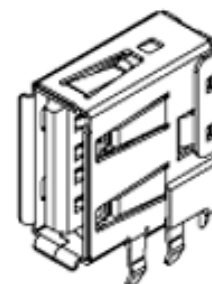

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2020)9139-DC (19
 Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[67329 Series](#)

Mates With

USB Type A Plug

Electrical

Current - Maximum per Contact

1.0A

Shield Type

Full Shield

Shielded

Yes

Material Info**Reference - Drawing Numbers**

Packaging Specification

PK-67329-001-001

Sales Drawing

SD-67329-801-001

This document was generated on 08/23/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION