

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0714391164](#)
Status: **Active**
Overview: 1.00mm Mezzanine (IEEE 1386)
Description: 1.00mm Mezz (IEEE 1386) Receptacle, Surface Mount, Dual Row, Vertical Stacking, Tube, 0.76µm Gold (Au), 64 Circuits

Documents:
[3D Model](#) [Packaging Specification PK-70873-0601-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [Packaging Specification PK-70873-063-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
UL E29179

General

Product Family PCB Receptacles
Series [71439](#)
Application Board-to-Board, Signal
Overview [1.00mm Mezzanine \(IEEE 1386\)](#)
Product Name 1.00mm Mezzanine (IEEE 1386)
UPC 800754350013

Physical


Circuits (Loaded) 64
Circuits (maximum) 64
Color - Resin Natural
Flammability 94V-0
Glow-Wire Capable No
Lock to Mating Part Yes
Mated Height 12.00mm
Material - Metal Phosphor Bronze
Material - Plating Mating Gold
Material - Plating Termination Tin
Material - Resin High Temperature Thermoplastic
Net Weight 1.270/g
Number of Rows 2
Orientation Vertical
PCB Locator Yes
PCB Retention None
PCB Thickness - Recommended 1.60mm
Packaging Type Tube
Pitch - Mating Interface 1.00mm
Plating min - Mating 0.762µm
Plating min - Termination 1.905µm
Polarized to PCB No
Surface Mount Compatible (SMC) N/A
Temperature Range - Operating -55° to +85°C
Termination Interface: Style Surface Mount

Electrical

Current - Maximum per Contact 1.0A
Voltage - Maximum 100V

Solder Process Data

Lead-freeProcess Capability REFLOW
Process Temperature max. C 260

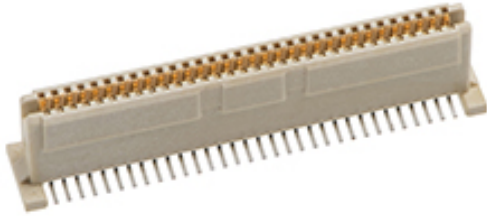

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[71439](#) Series

Mates With

[71436](#) 1.00mm Mezz (IEEE 1386) Plug. Be
sure to match like stack heights

Material Info

Reference - Drawing Numbers

Packaging Specification
Sales Drawing

PK-70873-0601-001, PK-70873-063-001
714391000-000

This document was generated on 08/03/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION