

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0731000097](#)
Status: **Active**
Overview: [SMB RF Connectors](#)
Description: 50 Ohms, SMB Right-Angle PCB, Bulkhead Jack Receptacle, 50 Pieces Per Tray

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-73598-0099-001 \(PDF\)](#)

General
Product Family RF/Coax Connectors
Series [73100](#)
Comments Feed-Through
Overview [SMB RF Connectors](#)
Product Name SMB
Style PCB
Type Subminiature
UPC 800753686342
Wire/Cable Type N/A


Physical
Gender Jack
Keying to Mating Part None
Net Weight 4.685/g
Orientation Right Angle
PCB Mounting Through Hole
PCB Thickness - Recommended 2.40mm
Packaging Type Tray
Panel Mount Yes
Panel Mount Method Bulkhead
Reverse Polar No

Electrical
Frequency 4 GHz
Impedance 50Ω
Power / Voltage VOLTAGE: 335 Vrms@Sea Level

Solder Process Data
Duration at Max. Process Temperature (seconds) 010
Lead-freeProcess Capability SMC&WAVE
Max. Cycles at Max. Process Temperature 002
Process Temperature max. C 260

Material Info

Reference - Drawing Numbers
Product Specification PS-73598-0099-001
Sales Drawing SD-73100-0097

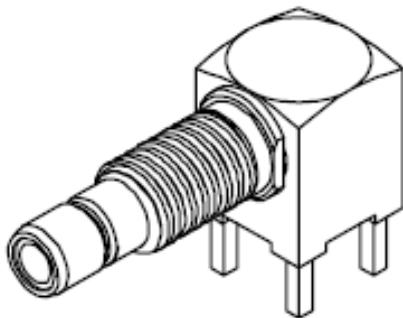

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2020)9139-DC (19 Jan 2021)	
Lead	
Halogen-Free Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[73100 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION